


## CIRCULAR FLEXIBLE BRAIDED TINNED COPPER ASSEMBLY

Mettex Ref	Customer Ref	Length "A"	Hole Dia. "B"	Hole Dia. "C"	Insulation
CCT-0002-0016	03-1948	200MM	M8	M8	N/A

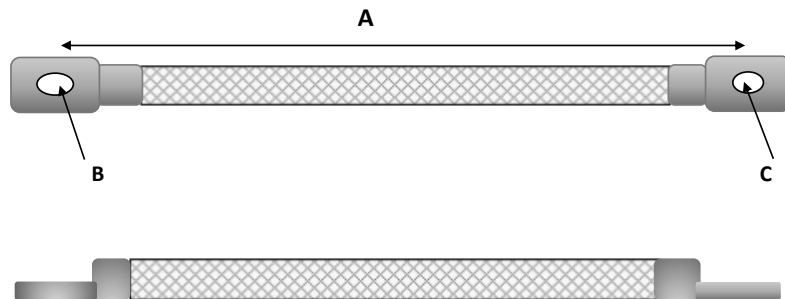

DIMENSIONS	RANGE	TOLERANCES
LENGTH	Up to 300mm	+/- 5mm
	300mm-1000mm	+/- 10mm
	1000m+	+/-20mm
WIDTH		+/-2mm
THICKNESS		+/-0.5mm
HOLE SIZE		+0.5mm, -0mm

<b>CUSTOMER NAME:</b>	RAPID ELECTRONICS	<b>NOMINAL DIMENSIONS:</b>	3.5mm diameter circular tnd cu braid, 200mm long b/w centres
<b>DATE:</b>	18.05.21	<b>BRAID MATERIAL:</b>	0.20 tinned copper braid to BSEN 13602:2013 & ASTM-B33
<b>TOLERANCE:</b>	SEE TOLERANCE TABLE	<b>INSULATION:</b>	N/A
<b>ISSUE No:</b>	1	<b>FERRULE:</b>	Tinned copper crimped tube terminals
<b>DRAWING No:</b>	03-1948	<b>ITEM/PART DESCRIPTION</b>	2.26sqmm earth strap