


Features:

This product includes the following features:

Current rating:	24A
Voltage Rating AC:	30V
Connector type:	4mm Banana test plug
Contact plating:	Nickel
Contact material:	Brass connector
Insulator material:	PVC
Length:	61.5mm Max
Cable diameter:	3.5mm
Termination type:	Screw

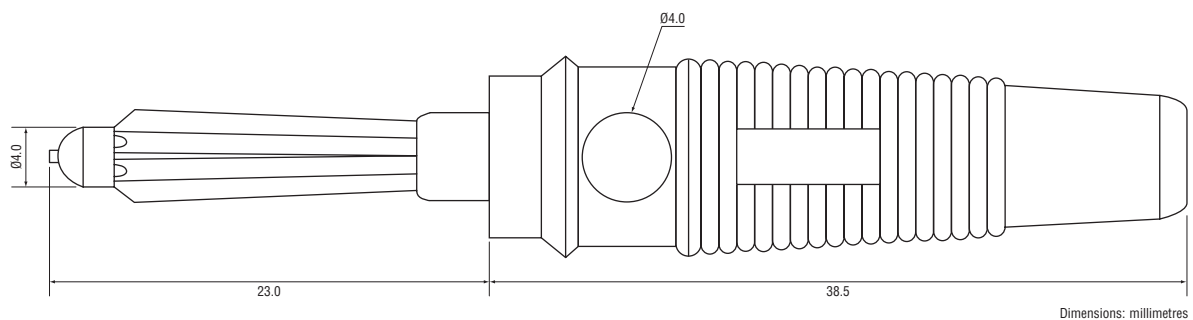

Specifications:

Material: Brass body nickel plated with PVC housing.

Part Number Table:

Description	Order code
Plug, 4mm, Red	17-2889
Plug, 4mm, Black	17-2890