


Linear Solenoids

Cylinder Solenoids

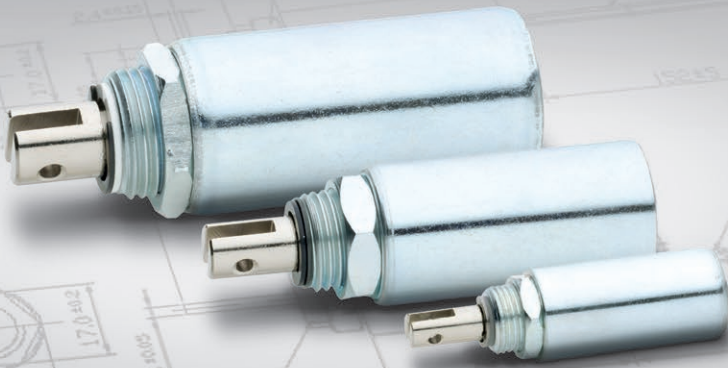


Stick and fix – easy mounting

Over-voltage capability

Extremely solid

Type

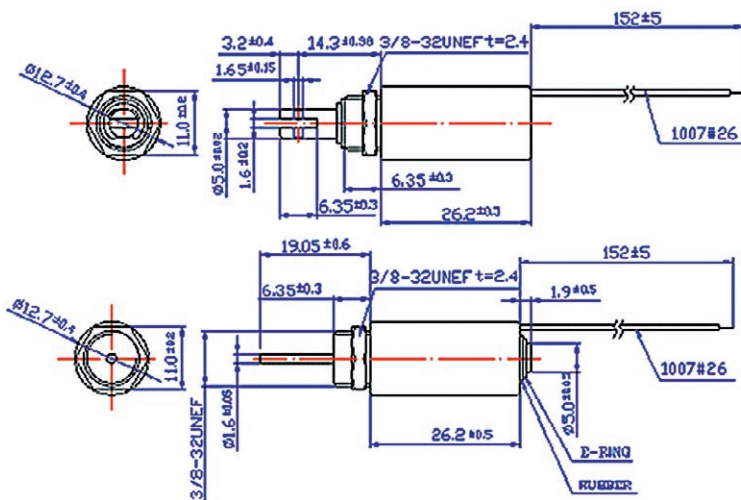

Description

Due to closed frame body tubular solenoid are highly efficient.

Useable in rough ambience.

Tubular Solenoid „small“

Stroke: 3 – 9 mm. Weight: 23,0 g

Coil Data

Relative duty (Percent)	100	50	25	10
Max. Performance (Watt)	4	8	16	40
Max. ED (Seconds)	∞	50	5	2

Solenoid Layout

Version:

Pull Solenoid

Push with return spring (not illustrated)


Current:

12 VDC (standard)

24 VDC (standard)

other voltages on request

Force-stroke-diagram (N/mm)

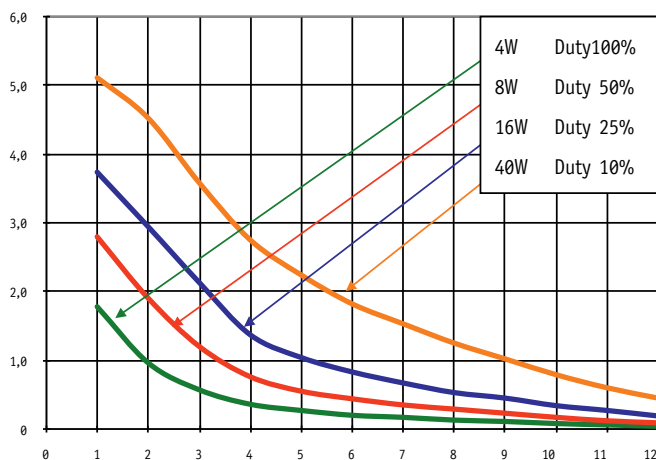

Special development

Do you like a costum designed version (for example frame, force, duty cycle etc.).

Please send us this form:

[Checklist \(PDF, 390 kB\)](#)