

New050804


Order code	Manufacturer code	Description
17-2244	2352-IEC-100 NR	4MM BLK PLUG TO R/A PLUG LEAD
17-2246	2352-IEC-100 RG	4MM RED PLUG TO R/A PLUG LEAD

New050804	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

4mm Safety Test Leads

Electro PJP – Standardised IEC 1010 Version


Photograph

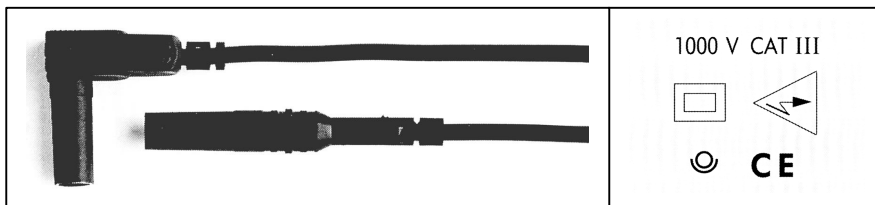

Specification

Cable insulation material	:	PVC
Connector insulation material	:	Polyamide
Connector contact material	:	Brass and bronze Ni
Cable cross sectional surface area	:	1.00mm ²
Voltage	:	1,000 V (Test 50/60 Hz 1mn > 7,400 V)
Maximum current	:	20 A
Overall contact resistance	:	100cm 20mΩ
Temperature range	:	-20°C to +80°C

Technical Drawing

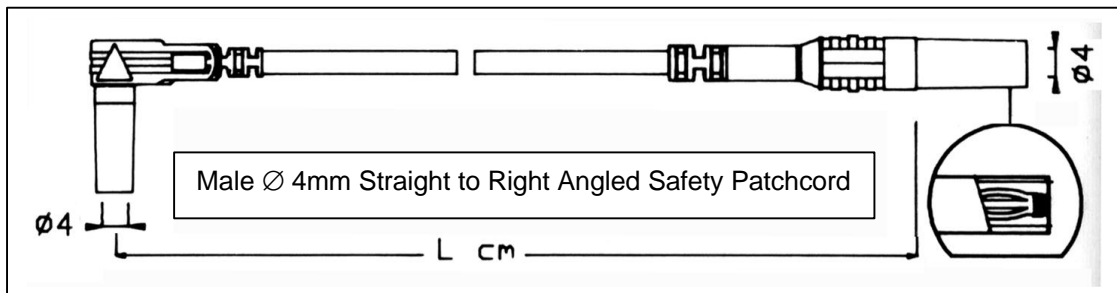

PJP Ref No.	Description	Length (cm)	Colour
2352-IEC-100-N	4mm Straight Plug to r/a Plug Safety Test Lead	100	Black
2352-IEC-100-R	4mm Straight Plug to r/a Plug Safety Test Lead	100	Red