
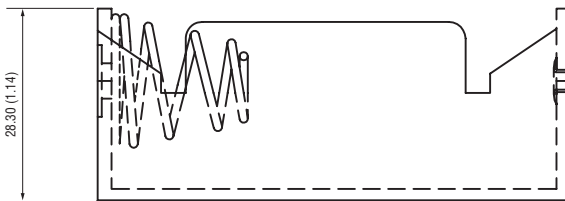


# Three 'D' Cell Holder with 9V Snaps

Order code: **18-0548**

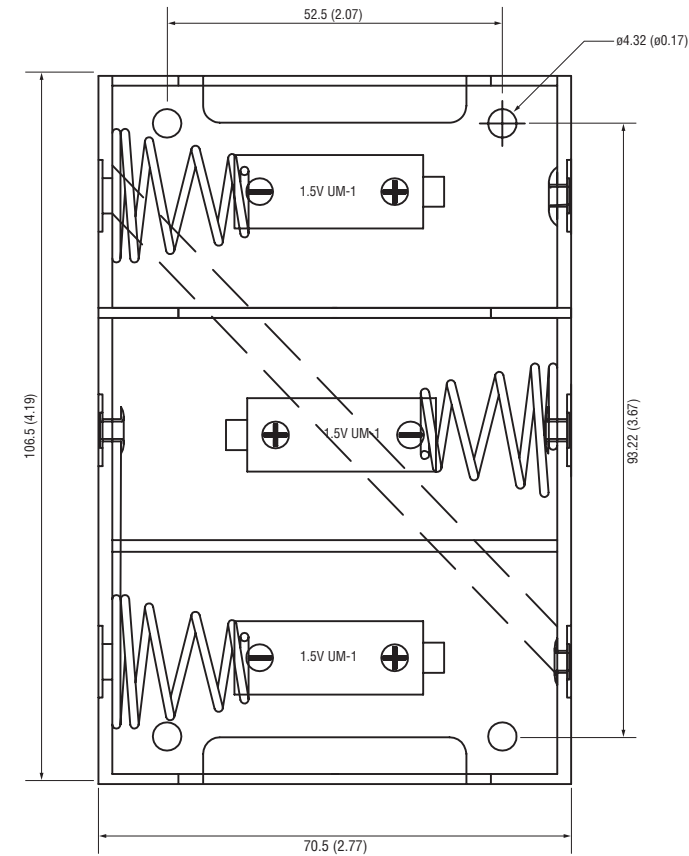

Tolerances	mm (inches)
Decimal	$\pm 0.5$ (0.020)
Fractional	$\pm 0.8$ (0.030)
Angular	$\pm 3^\circ$

## Specification:

Material:

Housing: black polypropylene

Flammability rating: UL94-HB, UL File No. E216959

Temperature range:  $-10^\circ\text{C}$  to  $+100^\circ\text{C}$

Rivets: brass, nickel plated

Spring: spring steel, nickel plated

9 volt snaps: brass, nickel plated

Contact resistance: under  $50\text{m}\Omega$  for  $+/-$  contacts per EIA-540J000

RoHS 2 compliant

