


Four 'D' Cell Holder with Solder Lugs

Order code: **18-0552**

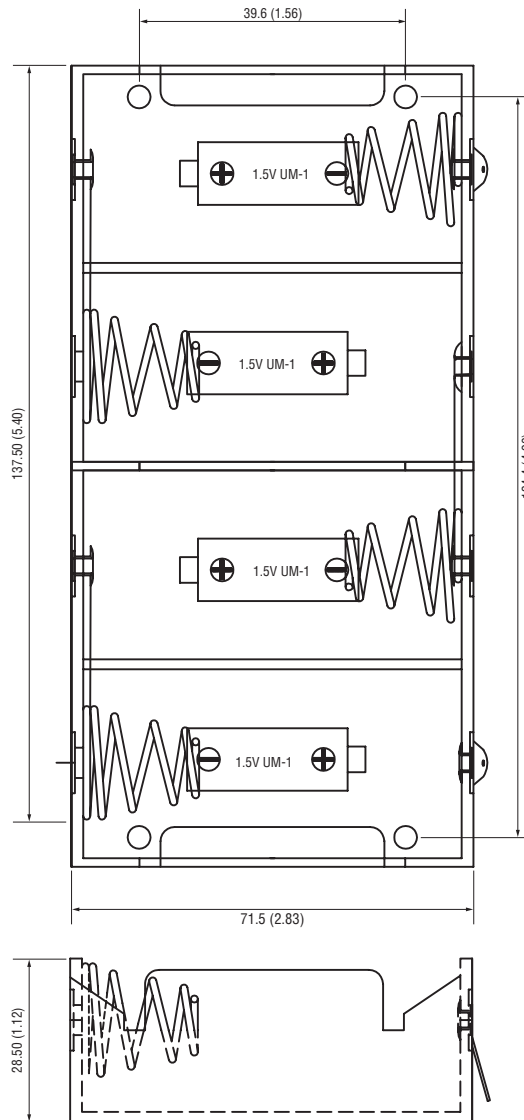

Specification:

Material:

Housing: black polypropylene

Flammability rating: UL94-HB, UL File No. E216959

Temperature range: -10°C to +100°C

Rivets: brass, nickel plated

Spring: spring steel, nickel plated

9 volt snaps: brass, nickel plated

Contact resistance: under 50mΩ for +/- contacts per EIA-540J000

RoHS 2 compliant

| Tolerances | mm (inches) |
|------------|--------------|
| Decimal | ±0.5 (0.020) |
| Fractional | ±0.8 (0.030) |
| Angular | ±3° |

