




Two 'C' Cell Holders with Snap Fastener

Order code: **18-0554**

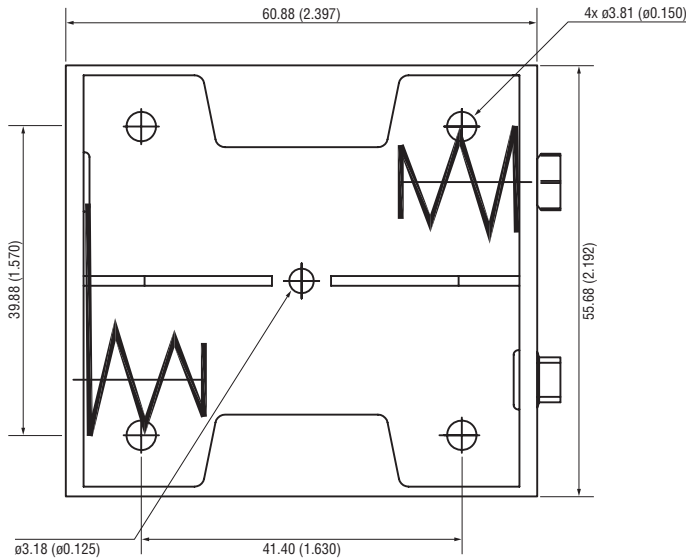

Specification:

Material:

Plastic material: polypropylene

Flammability rating: UL94-HB, UL File No. E216959

Temperature range: -10°C to +100°C

Springs: spring steel, nickel plated

Wire: 26 AWG, UL1007, CSA

Rivets: brass, nickel plated

9 Volt snaps: brass, nickel plated



Contact resistance: under 50mΩ for +/- contacts per EIA-540J000

RoHS 2 compliant

Mounting instructions:

Use 2x 56 machine screws or eyelets 0.089in OD by 0.15in flange
Stimpson GS-3 series or equivalent.

Also adhesives and double sided tapes work well.

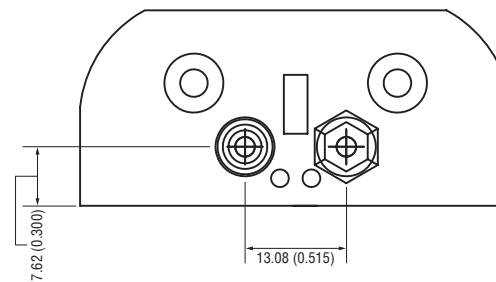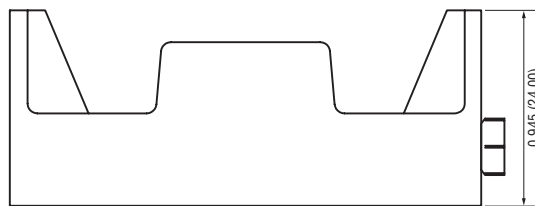

Tolerances	mm (inches)
Decimal	±0.5 (0.020)
Fractional	±0.8 (0.030)
Angular	±3°