


# Linear Solenoids

## Cylinder Solenoids

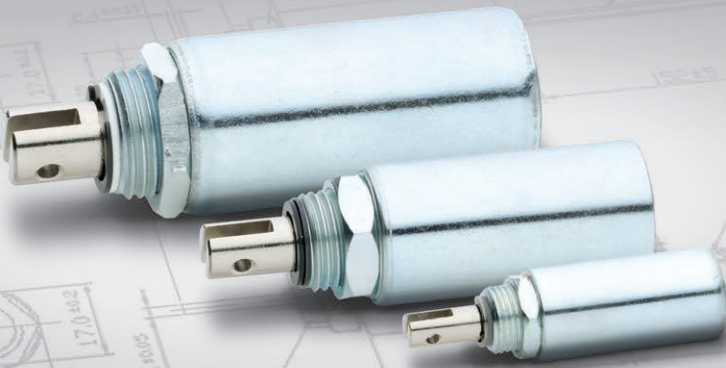


Stick and fix – easy mounting


Over-voltage capability

Extremely solid

### Type

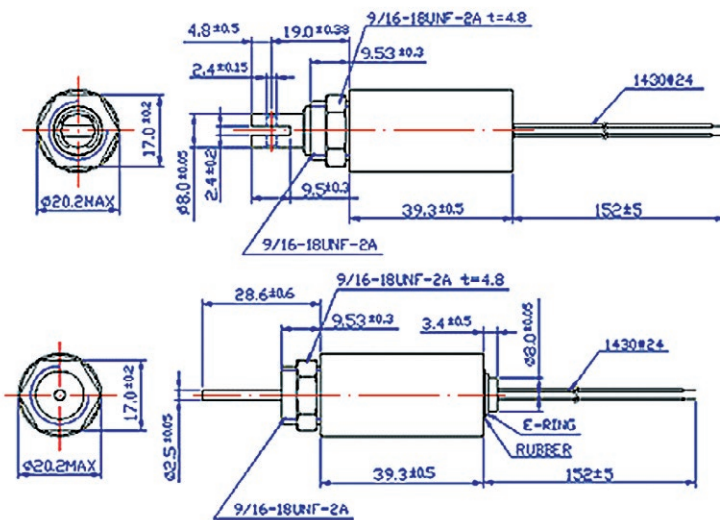

### Force-stroke-diagram (N/mm)

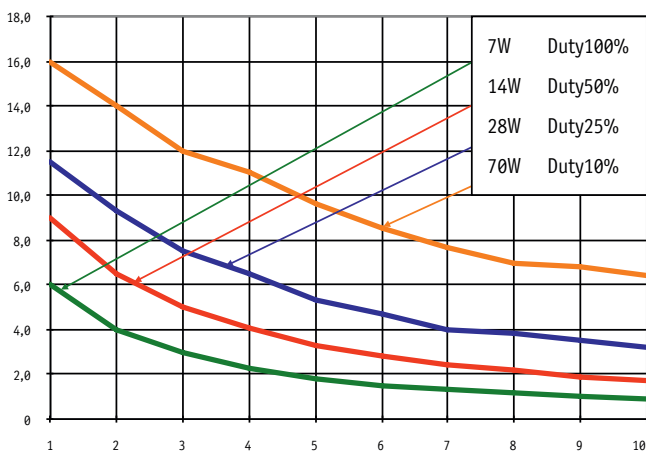

### Description

Due to closed frame body tubular solenoid are highly efficient.

Useable in rough ambience.

Tubular Solenoid „small“

Stroke: 10 – 18 mm. Weight: 81 g

### Coil Data

Relative ED (Percent)	100	50	25	10
Max. Performance (Watt)	7	14	28	70
Max. ED (Seconds)	∞	230	25	6

### Solenoid Layout

Version:

Pull Solenoid

Push with return spring (not illustrated)

Current:

12 VDC (standard)

24 VDC (standard)

other voltages on request

### Special development

Do you like a costum designed version (for example frame, force, duty cycle etc.).

Please send us this form:

[Checklist \(PDF, 390 kB\)](#)