

2.54mm PCB connectors

| Order code | Manufacturer code | Description |
|------------|-------------------|------------------------------------|
| 22-2540 | n/a | 0.156" 10W CRIMP TERM.HOUSING (RC) |
| 22-2515 | n/a | 0.156" 5W CRIMP TERM.HOUSING (RC) |
| 22-2520 | n/a | 0.156" 6W CRIMP TERM.HOUSING (RC) |
| 22-2530 | n/a | 0.156" 8W CRIMP TERM.HOUSING (RC) |
| 22-2500 | n/a | 0.156" 2W CRIMP TERM.HOUSING (RC) |
| 22-2505 | n/a | 0.156" 3W CRIMP TERM.HOUSING (RC) |
| 22-2510 | n/a | 0.156" 4W CRIMP TERM.HOUSING (RC) |

| | |
|--|--------------------------|
| 2.54mm PCB connectors | Page 1 of 2 |
| The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E. | Revision A 20/02/2007 |

0.156" CRIMP HOUSING




SPECIFICATION

VOLTAGE RATING : AC, DC, 250V max

CURRENT RATING : 7A, max

APPLICABLE PC BOARD THICKNESS : .063" (1.6mm)

Material: Nylon 6/6 UL 94V-2

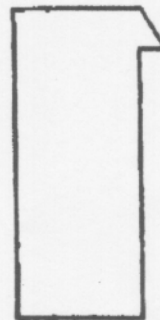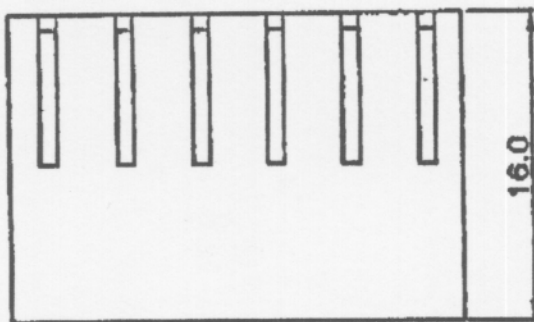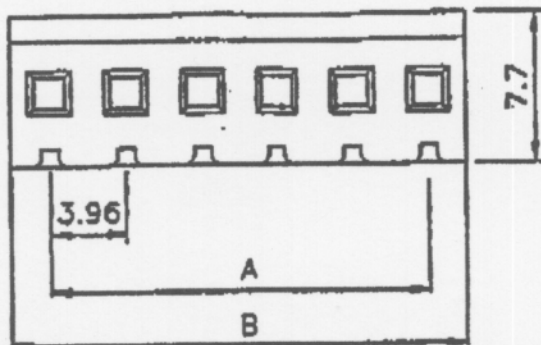

| Circuits | Dim A | Dim B |
|----------|-------|-------|
| 2 | 3.96 | 8.5 |
| 3 | 7.92 | 12.5 |
| 4 | 11.88 | 16.4 |
| 5 | 15.84 | 20.4 |
| 6 | 19.80 | 24.4 |
| 8 | 27.72 | 32.3 |
| 10 | 35.64 | 40.2 |