


# MPP ARCA 3020

**FIBOX**  
Enclosing innovations

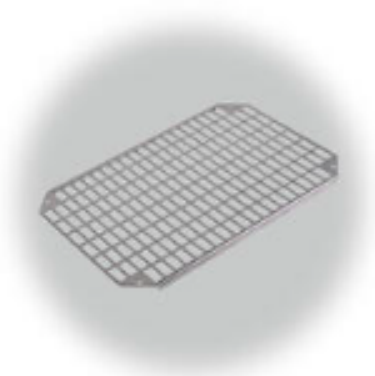

Sample image

**Order symbol:** MPP ARCA 3020

**Product nbr:** 8120751

**Description:** Mounting plate perforated (250x150x2 mm - 26x11 mm)


**Remarks:** Galvanized steel. for size 300x200x150

**EAN:** 6418074082725

**El. number:**

- Finland: 3423832
- Denmark:
- Sweden:

**Including:**

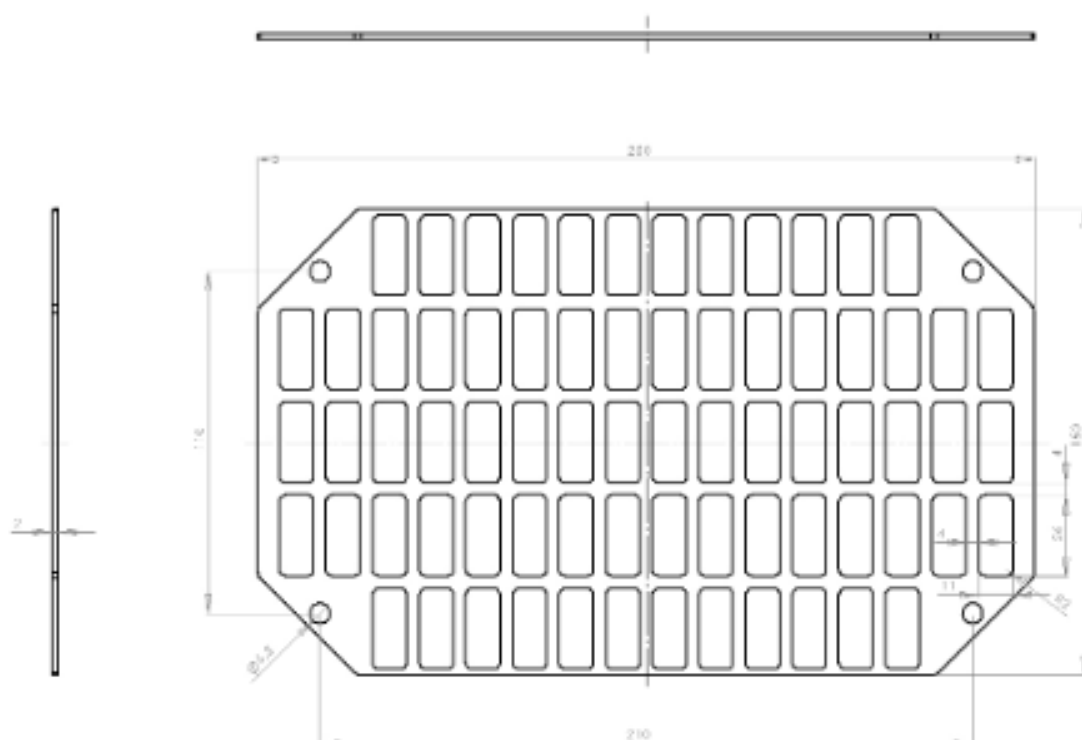

Dimensions:	Length	Width	Height
mm:		150	250
inch:		5.91	9.84

#### Materials:

Material:

Base colour:

Cover colour:

Gasket material:

#### Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

#### Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

#### Certificates: