


MPP ARCA 7050

FIBOX
Enclosing innovations

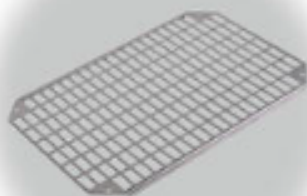

Sample image

Order symbol: MPP ARCA 7050

Product nbr: 8120758

Description: Mounting plate perforated (630x430x2 mm - 26x11 mm)


Remarks: Galvanized steel, for size 700x500x300

Including:

EAN: 6418074082794

El. number:

- Finland: 3423845
- Denmark:
- Sweden:

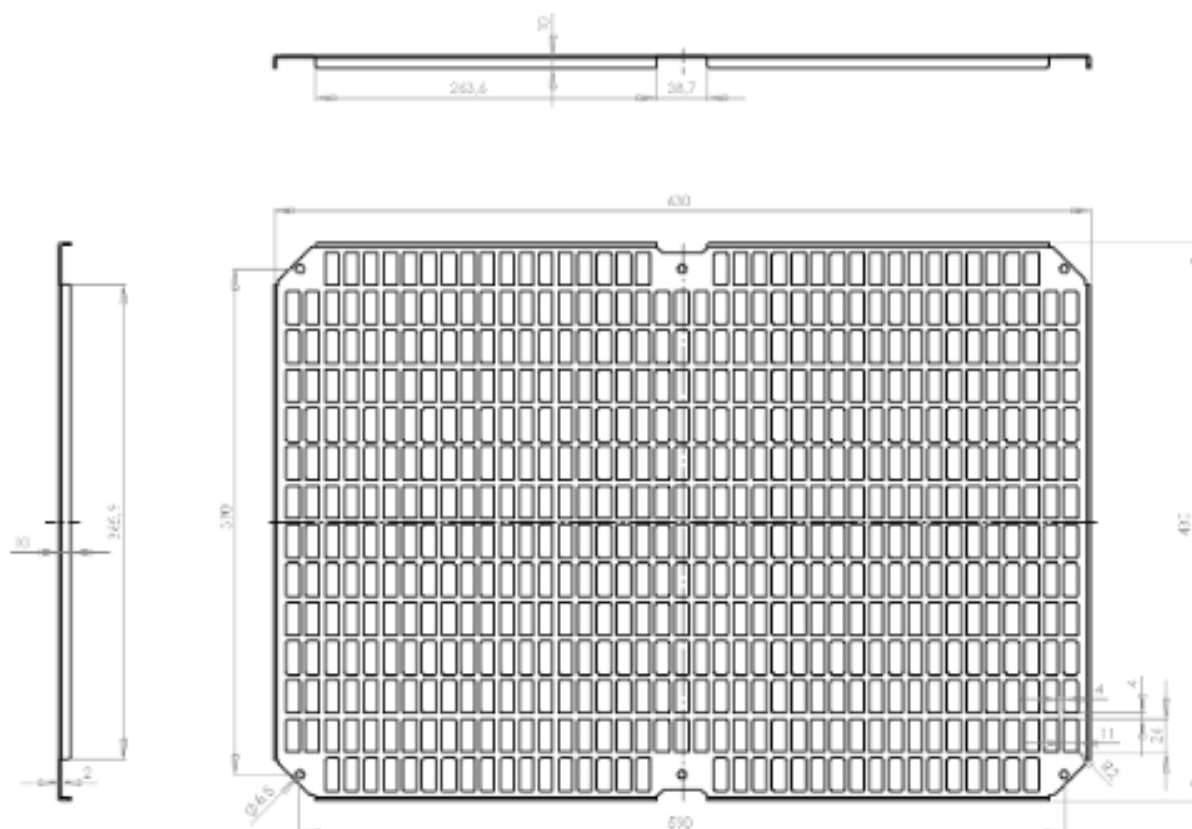

Dimensions:

	Height	Width	Depth
mm:	630	430	2
inch:	0	0	0.08

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Certificates: