

MPS ARCA 6040

FIBOX

Enclosing innovations



Sample image

Order symbol: MPS ARCA 6040

Product nbr: 8120736

Description: Mounting plate
(550x350x2 mm)


Remarks: Galvanized steel. for size
600x400x210

Including:

EAN: 6418074082596

El. number:

- Finland: 3423814
- Denmark: 8212094440
- Sweden: 2500186

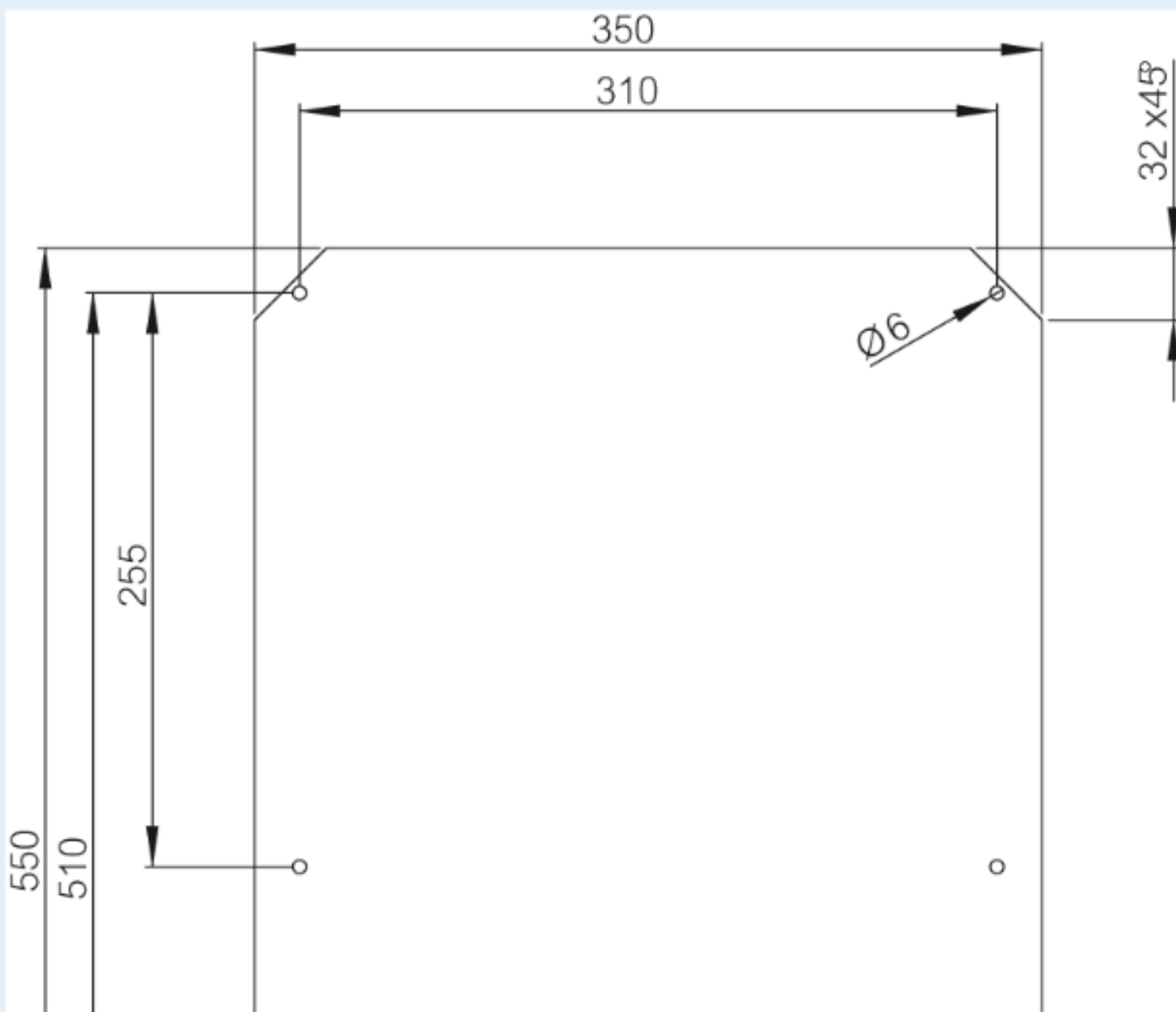

s=2

Dimensions:	Height	Width	Depth
mm:	550	350	2
inch:	21.65	13.78	0.08

Materials:
Material:
Base colour:
Cover colour:
Basket material:

Rating:	
Ingress protection (EN 60529):	
Impact Resistance (EN 62262):	
Electrical insulation:	Not insulated
Halogen free (DIN/VDE 0472, Part 815):	0
UV resistance:	-
Flammability Rating:	
Glow Wire Test (IEC 695-2-1) °C:	C
NEMA Class	

Temperatures:

Temperature °C (short term):
Temperature °C (continuous):
Temperature °F (short term):
Temperature °F (continuous):

Certificates: