



Nuts Screws Washers and Bolts

Order code	Manufacturer code	Description
33-2952	n/a	M3 10MM C/S POZI SCREWS PACK 100 (RC)

Nuts Screws Washers and Bolts	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

Pozidriv® cross recessed flat head machine screws

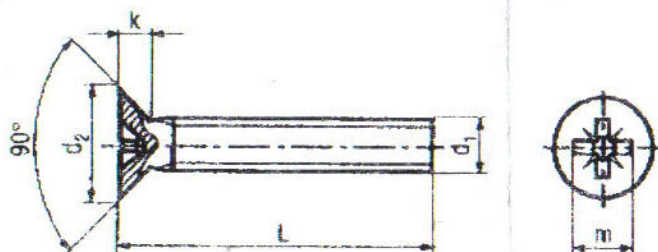

DIN 965 A	4.8	
~ISO 7046		Type Z
ANSI B 18.6.7 M		
BN 3333 <input type="checkbox"/> zinc plated		

Material: Steel
 Property class: 4.8

Tensile strength R_m : min. 420 MPa (60900 psi)
 Yield strength $R_{p0.2}$: min. 340 MPa (49300 psi)

d1	M2	M2.5	M3	M4	M5	M6
d2	3.8	4.7	5.6	7.5	9.2	11
k max.	1.2	1.5	1.65	2.2	2.5	3
m	2.2	2.5	2.8	4	4.4	6.1
Driver size	1	1	1	2	2	3
min. pen. depth	0.92	1.22	1.48	1.6	2.05	2.46
gauge max.	1.17	1.47	1.73	2.06	2.51	2.92
Proof load (N)	600	990	1560	2720	4400	6230