


## Fixings and PCB Mounts


Order code	Manufacturer code	Description
33-5300	n/a	STURDIPOST HEX 6.4 X 13M3 I/S
33-5305	n/a	STURDIPOST HEX 6.4 X 25 M3 I/S
33-5310	n/a	STURDIPOST HEX 8 X 16 M4 I/S
33-5315	n/a	STURDIPOST HEX 8 X 25 M4 I/S
33-5320	n/a	STURDIPOST HEX 8 X 39 M4 I/S

Fixings and PCB Mounts	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003


**TYPE S/S**

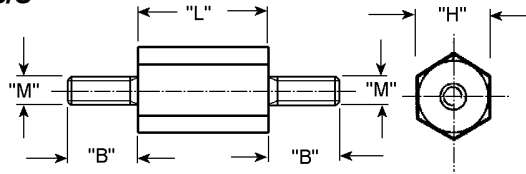

**TYPE I/S**

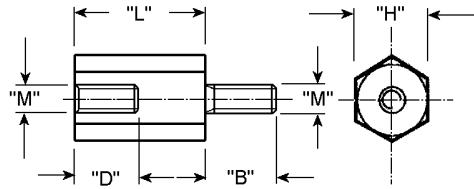

**TYPE I/I**

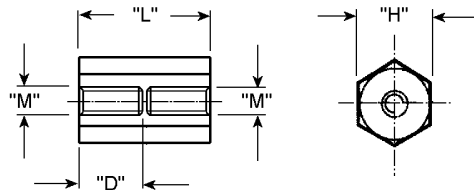

**HTNSP**

THREADED NYLON PILLARS

Part No.	Thread "M"	"H" mm	"B" mm	"D" mm	"L" mm	Type
HTNSP-M2-6.4-L-TYPE	M2	6.4	6.0	6.0	15mm to 50mm (available in 1mm increments)	I/I - female/female I/S - female/male S/S - male/male
HTNSP-M2.5-6.4-L-TYPE	M2.5	6.4	6.0	6.0	15mm to 50mm (available in 1mm increments)	
HTNSP-M3-6.4-L-TYPE	M3	6.4	6.0	6.0	15mm to 50mm (available in 1mm increments)	
HTNSP-M4-8-L-TYPE	M4	8.0	6.0	6.0	15mm to 75mm (available in 1mm increments)	
HTNSP-M5-9.5-L-TYPE	M5	9.5	10.0	10.0	20mm to 75mm (available in 1mm increments)	
HTNSP-M6-12.7-L-TYPE	M6	12.7	12.7	12.7	25mm to 75mm (available in 1mm increments)	

Material: Nylon 6 - natural, UL 94 V-2  
 Insert: Brass  
 Std. Pk.: 100 pcs.

Note:

