



EMAS ELEKTROTEKNİK MAKİNA
SANAYİ VE TİCARET A.Ş


Ziya Gökalp Mah. İkitelli Organize Sanayi Bölgesi
Atatürk Bulvarı No:50 34490 Başakşehir / İstanbul /
TÜRKİYE

Telefon : +90 212 549 22 52

Faks : +90 212 549 25 80

Web : www.emasas.com.tr

Technical Specifications : IF5P024XM05

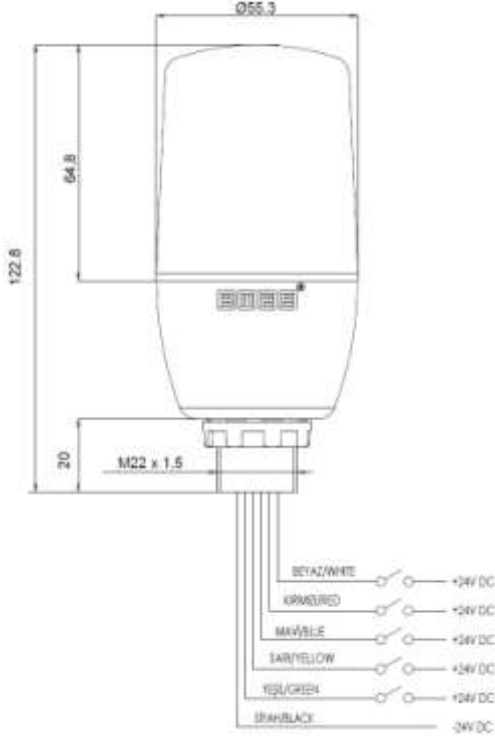

Order Code:

IF5P024XM05

43-3564

Technical Information :

Body:

Heat resistant, clear vision polycarbonate signal modules

Easy and tool less connection

Easy wiring

General Specifications :

Operating Temperature	-5 to +40°C
Electrical life	10,000 hours
Protection degree	IP65

Standards:



Electrical Informations :

General Specifications :

Operating voltage	Ue	24V DC
Insulation voltage	Ui	300V
Sound level	SL	80 to 90dB
Power consumption (Red)	P1	408mW
Power consumption (Yellow)	P2	552mW
Power consumption (Blue)	P3	360mW
Power consumption (Green)	P4	360mW
Power consumption (White)	P5	960mW