



EMAS ELEKTROTEKNİK MAKİNA  
SANAYİ VE TİCARET A.Ş


Ziya Gökalp Mah. İkitelli Organize Sanayi Bölgesi  
Atatürk Bulvarı No:50 34490 Başakşehir / İstanbul /  
TÜRKİYE

Telefon : +90 212 549 22 52

Faks : +90 212 549 25 80

Web : www.emasas.com.tr

Technical Specifications : IF5P024ZM05

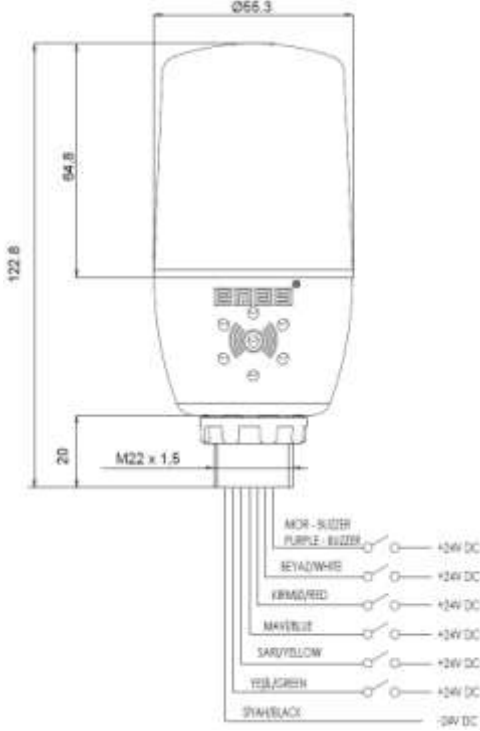

**Order Code:**

IF5P024ZM05

43-3565

Technical Information :

**Body:**

Heat resistant, clear vision polycarbonate signal modules

Easy and tool-less connection

Easy wiring

**General Specifications :**

Operating Temperature	-5 to +40°C
Electrical life	10,000 hours
Protection degree	IP65

**Standards:**



Electrical Informations :

**General Specifications :**

Operating voltage	Ue	24V DC
Insulation voltage	Ui	300V
Sound level	SL	80-90dB
Power consumption (Red)	P1	408mW
Power consumption (Yellow)	P2	552mW
Power consumption (Blue)	P3	360mW
Power consumption (Green)	P4	360mW
Power consumption (White)	P5	960mW
Power consumption (Buzzer)	P5	480mW