



EMAS ELEKTROTEKNİK MAKİNA
SANAYİ VE TİCARET A.Ş


İkitelli Organize Sanayi Bölgesi Mah. Atatürk
Bulvarı No: 50 / A 34490 Başakşehir / İstanbul /
TÜRKİYE

Telefon : +90 212 549 22 52

Faks : +90 212 549 25 80


Web : www.emasas.com.tr

Technical Specifications : IF5T024ZM05-1

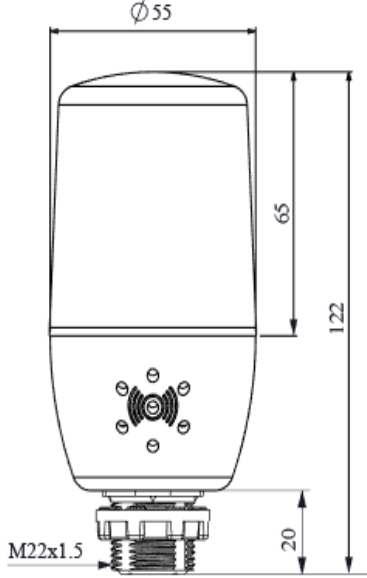

Order Code:

IF5T024ZM05-1

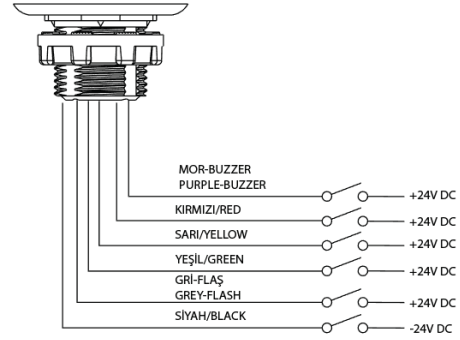

Technical Information :

Body:

- Heat resistant, clear vision polycarbonate signal modules
- Easy and tool less connection thanks
- Easy wiring

-Operating Temperature	-25 / +70 °C
-Electrical life	10.000 hours
-Protection degree	IP65
-Cable Length	1 m

Standards:



Electrical Informations :

General Specifications :

-Operating voltage	Ue	24 V AC
-Insulation voltage	Ui	300 V
-Sound level	SL	90 dB
-Power consumption(Red)	P	0.80W
-Power consumption(Yellow)	P	0.80W
-Power consumption(Green)	P	0.80W
-Power consumption(Buzzer)	P	0.82W