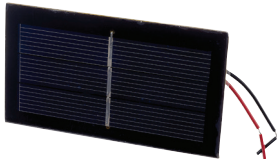
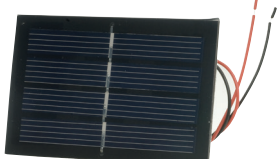
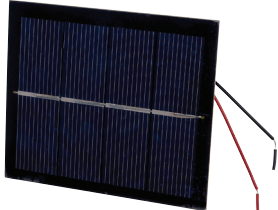
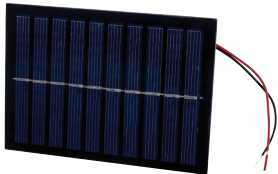


## Features:

- Using crystal type silicon solar cells
- Small size
- Light Weight
- High efficiency
- Output with 2 solder Line, 24# AWG Red and black wires; length: 30 cm
- Long life and durable
- **IP65** ability

## Specifications:

Order code	MPN	Solar Cell	Voltage (V)	Current (mA)	Power (W)	Dimensions (mm)	Power Tolerance (%)	Temperature Coefficient (%/°C)
55-0010	OPL15A25101		1.5	250	0.37	90x50x3	+/-3	-0.45
55-0012	OPL20A25101		2.0	250	0.5	90x60x3	+/-3	-0.45
55-0014	OPL20A50101		2.0	500	1	90x105x3	+/-3	-0.45
55-0016	OPL50A23101		5.0	230	1.15	90x125x3	+/-3	-0.45