


Typ/Type

UI30/7,5

Sicherheitstransformator
 VDE 0570 / EN 61558 / ENEC10
 UL 506 / CSA geprüft
 Vakuumverguss
 Temperaturklasse ta70°C/B
 Cul-Gewicht: 50 g
 Gesamt-Gewicht: 150 g

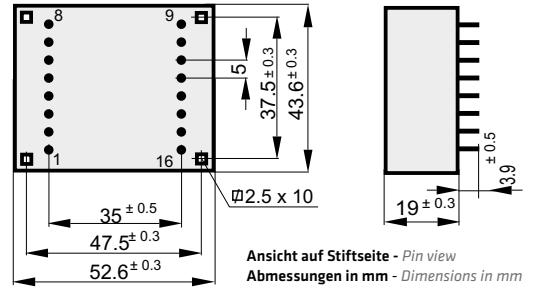

Nennleistung/Nominal power

4.0 VA

Safety transformer
 VDE 0570 / EN 61558 / ENEC10
 UL 506 / CSA geprüft
 Vacuum casting
 Temperature class ta70°C/B
 Cul weight: 50 g
 Total weight: 150 g



Bestell Nr. <i>Order No.</i>	Primär [V] <i>Primary</i>	Sekundär [V] <i>Secondary</i>	Strom [mA] <i>Current</i>	Stiftbelegung <i>Pin configuration</i>	Leerlaufspannung [V] <i>No load voltage</i>	Prüfzeichen / Approvals		
						VDE	UL 1585	UL 506
FLG30.7/60031-1	2x115	2x6	2x333	1-3+6-8 / 9-10+15-16	2x9,20	●		●
FLG30.7/60063-1	2x115	2x7,5	2x266	1-3+6-8 / 9-10+15-16	2x11,40	●		●
FLG30.7/60032-1	2x115	2x9	2x222	1-3+6-8 / 9-10+15-16	2x13,70	●		●
FLG30.7/60004-1	2x115	2x12	2x166	1-3+6-8 / 9-10+15-16	2x17,90	●		●
FLG30.7/60005-1	2x115	2x15	2x133	1-3+6-8 / 9-10+15-16	2x22,40	●		●
FLG30.7/60006-1	2x115	2x18	2x111	1-3+6-8 / 9-10+15-16	2x24,00	●		●
FLG30.7/60033-1	2x115	2x24	2x83	1-3+6-8 / 9-10+15-16	2x35,40	●		●

Trenntransformator / isolation transformer