


Typ/Type

UI30/10,5

Sicherheitstransformator
 VDE 0570 / EN 61558 / ENEC10
 UL 506 / CSA geprüft
 Vakuumverguss
 Temperaturklasse ta70°C/B
 Cul-Gewicht: 60 g
 Gesamt-Gewicht: 180 g

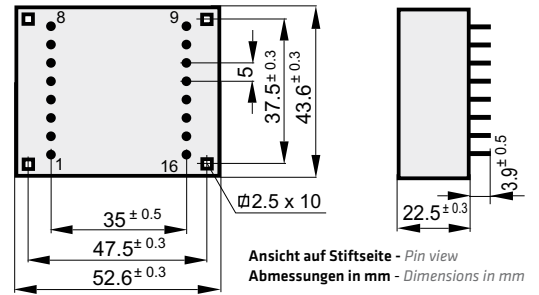

Nennleistung/Nominal power

6.0 VA

Safety transformer
 VDE 0570 / EN 61558 / ENEC10
 UL 506 / CSA approved
 Vacuum casting
 Temperature class ta70°C/B
 Cul weight: 60 g
 Total weight: 180 g



Bestell Nr. <i>Order No.</i>	Primär [V] <i>Primary</i>	Sekundär [V] <i>Secondary</i>	Strom [mA] <i>Current</i>	Stiftbelegung <i>Pin configuration</i>	Leerlaufspannung [V] <i>No load voltage</i>	Prüfzeichen / Approvals		
						VDE	UL 1585	UL 506
FLG30.10/60034-1	2x115	2x6	2x500	1-3+6-8 / 9-10+15-16	2x8,40	●		●
FLG30.10/60067-1	2x115	2x7,5	2x400	1-3+6-8 / 9-10+15-16	2x10,40	●		●
FLG30.10/60035-1	2x115	2x9	2x333	1-3+6-8 / 9-10+15-16	2x12,40	●		●
FLG30.10/60007-1	2x115	2x12	2x250	1-3+6-8 / 9-10+15-16	2x16,30	●		●
FLG30.10/60008-1	2x115	2x15	2x200	1-3+6-8 / 9-10+15-16	2x20,30	●		●
FLG30.10/60009-1	2x115	2x18	2x166	1-3+6-8 / 9-10+15-16	2x23,80	●		●
FLG30.10/60036-1	2x115	2x24	2x125	1-3+6-8 / 9-10+15-16	2x31,90			●

Trenntransformator / isolation transformer