


Graduated Cylinders - Glass, Class-B with Hexagonal base

CH0345C-WT

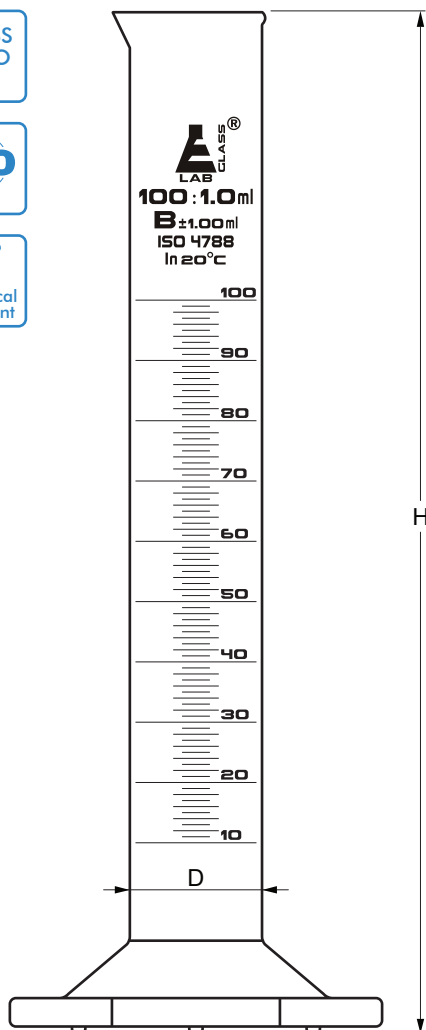

Capacity	100 ml
Sub. Division (ml)	1.0 ml
Tolerance	± 1.00 ml
Overall Height (H)	245 mm
Outer Dia. (D)	32 mm
Max. recommended temperature	250°C

- Class-B graduated cylinder with hexagonal base and spout
- Made of borosilicate glass 3.3
- Meets ISO 4788 standard
- Uniform wall thickness no wedge errors
- Chemical resistant white printing