


LED Drivers Constant Current

PSU-SNP CC series 0 ~ 40W

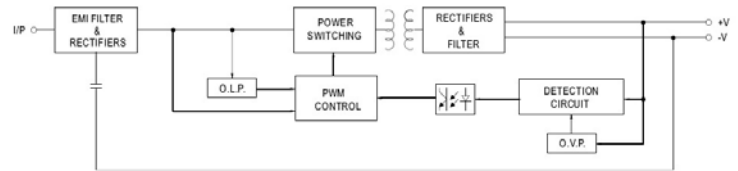

To support our extensive range of LED products we offer a comprehensive range of power supplies designed specifically for LED applications. The SNP-CC series facilitate flexible connection via covered screw terminals

Features

- Constant Current mode power supply
- Compact packages
- Covered Screw terminal connection
- Fully encapsulated to IP20
- High efficiency
- Short circuit / Over current protection

Compliance

- Magnetic Emission EN55015
- Harmonic EN61000-3-2
- Immunity EN61547
- Safety EN61347-1, EN61347-2
- TUV Approval
- UL approvals on certain types

Specifications

PART NUMBER	AC INPUT	OUTPUT VOLTAGE	OUTPUT CURRENT	RATED POWER	PF	DIMENSIONS (mm)
PSU-SNP6-350IF	200~240v	17.5vdc	350mA	0 ~ 6W	0.5	98.4x45.6x10.7
PSU-SNP6-700IF		9vdc	700mA			
PSU-SNP8-350IL		12-24vdc	350mA	0 ~ 8W	0.8	94.5x46.2x19.5
PSU-SNP8-500IL		8-16vdc	500mA			
PSU-SNP8-700IL		6-12vdc	700mA			
PSU-SNP12-350IF		34vdc	350mA	0 ~ 12W	0.5	127.3x49.8x10.7
PSU-SNP12-700IF		17vdc	700mA			
PSU-SNP15-350IF		42vdc	350mA	10 ~ 15W	≥0.5	128.4x50.6x13.5
PSU-SNP15-500IF		30vdc	500mA			
PSU-SNP15-700IL		21vdc	700mA			123x44.6x19.2
PSU-SNP20-350IF		56vdc	350mA	11 ~ 20W	0.5	154x50x14
PSU-SNP20-500IF		40vdc	500mA			
PSU-SNP20-700IF		29vdc	700mA			
PSU-SNP30-500IF		60vdc	500mA	15 ~ 30W	0.9	159.9x57.8x18
PSU-SNP30-700IF		42vdc	700mA	15 ~ 30W		
PSU-SNP30-1050IF		28.6vdc	1050mA			
PSU-SNP30-1400IF		21vdc	1400mA			
PSU-SNP40-500IF		80vdc	500mA	20 ~ 40W	0.9	159.9x57.8x18
PSU-SNP40-700IF		57.1vdc	700mA			
PSU-SNP40-1050IF		38vdc	1050mA			
PSU-SNP40-1400IF	28.5vdc	1400mA				
PSU-SNP40-2100IF	19.0vdc	2100mA				

Notes:

This data is for selection reference only. Please check the full data sheet for the latest specifications
Specifications may be subject to change without notice