


# Porcelain terminal blocks

**SERIES 103**  
 Porcelain connectors - 2 and 3 pole without wire protector, 16mm<sup>2</sup>

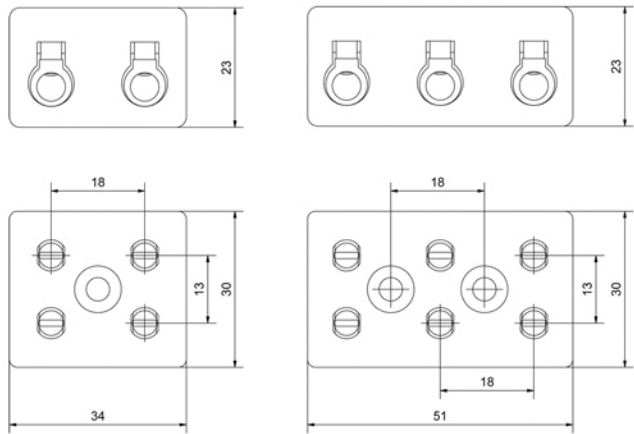

**FEATURES**

Series 103 porcelain connectors are suitable for all applications where thermoplastic materials would not have sufficient heat resistance capabilities. The connectors shown are glazed to prevent moisture absorption (base is unglazed) and are available in 32 amp rating only. None of the connectors on this page carry marking.

Nominal Cross-Section mm <sup>2</sup>	6,0
Voltage Rating V	450

**TECHNICAL DETAILS**

<b>Connection:</b>	screw conductor size 0.5mm <sup>2</sup> -16mm <sup>2</sup>
<b>Fixing:</b>	by screw or rivet size Ø 4.5mm
<b>Mouldings:</b>	porcelain C 111 EN 60672 glazed porcelain, white, except lower surface continuous working temperature 1000 °C
<b>Contacts:</b>	brass, plated, continuous working temperature 350 °C
<b>Screws:</b>	M4:  max. 1.2 Nm steel, zinc plated, chromed
<b>Current rating:</b>	to EN 60 598: 32 A at T 100 °C to EN 60 998: 41 A at T 100 °C
<b>Stripping length:</b>	9.5mm - 10mm

PART NUMBER CODE

For 2 pole  
 Enter 4  
 For 3 pole  
 Enter 6

1	0	3	-	-	-	-	-	-	-	-	-	-
---	---	---	---	---	---	---	---	---	---	---	---	---