

**B7**  
**DC LINEAR SOLENOID**



Ø12 WITH HEX. SOCKET FOR 5.5 KEY WHEN LOCKING NUT (END MOUNT)

**Availability**  
PULL - LONG STROKE  
THRUST (PUSH) - STANDARD STROKE

**Solenoid shown in energised position**


Weight complete 1.1Kg  
Plunger weight 180g max

Forces shown are at working temperature

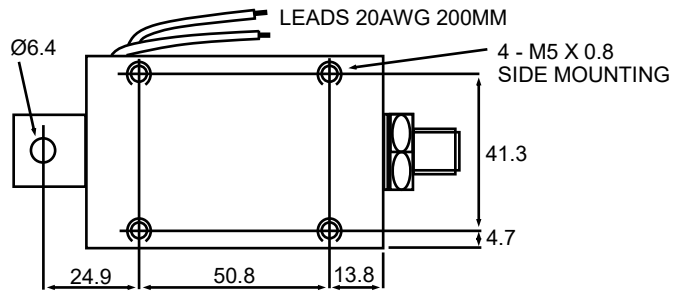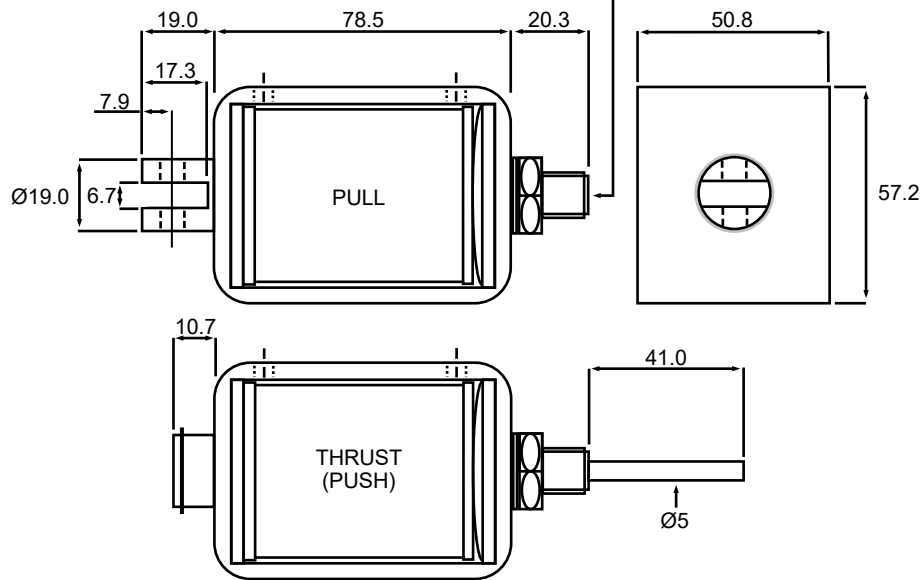


DIMENSIONS IN MM

**BDC7L**

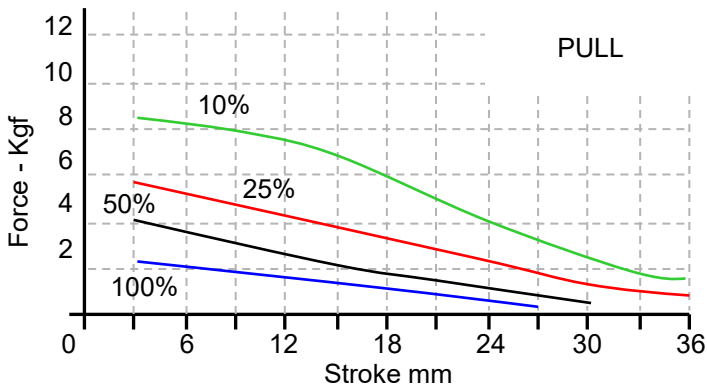

**BDC7**

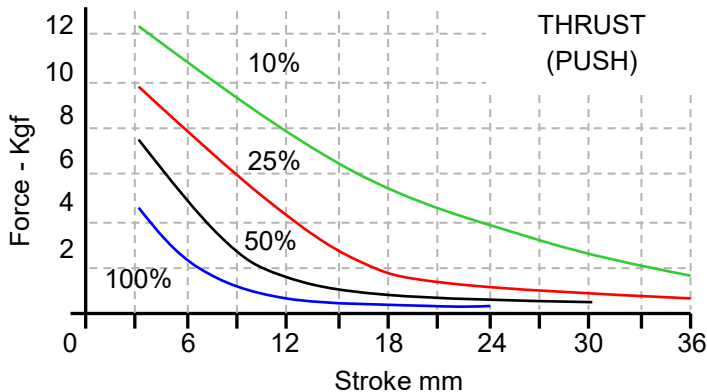

**DC Watts**

- 100% Rtg = 20W
- 50% Rtg = 40W
- 25% Rtg = 80W
- 10% Rtg = 200W

\*\* Please note: Fixing, plunger coupling, thrust rods and lead length can all be customised \*\*  
We reserve the right to alter or amend designs without prior notice.