

Standard Quick Wire Plugs


Types K, J, T
(IEC Colour Code)



- Standard connector with solid round plug pins
- Easy 'jab-in' connection for rapid termination, just push wire in and tighten screw
- Contacts are polarised to prevent incorrect connection
- Available in Thermocouple types K, J, T
- For Types K, J, T contacts are made from true Thermocouple alloys
- Colour coded in accordance with IEC specification
- Maximum continuous temperature 220 deg°C

T/C Type	Colour Code (IEC)	+Positive Contact (alloy type)	-Negative Contact (alloy type)	Manufacturer's Part Number	Rapid Order Code
K	Green	+Nickel Chromium	-Nickel Alloy	XE-1411-001	61-3025
J	Black	+Iron	-Copper Nickel	XE-1471-001	61-3026
T	Brown	+Copper	-Copper Nickel	XE-1501-001	61-3027

Schematic Drawing

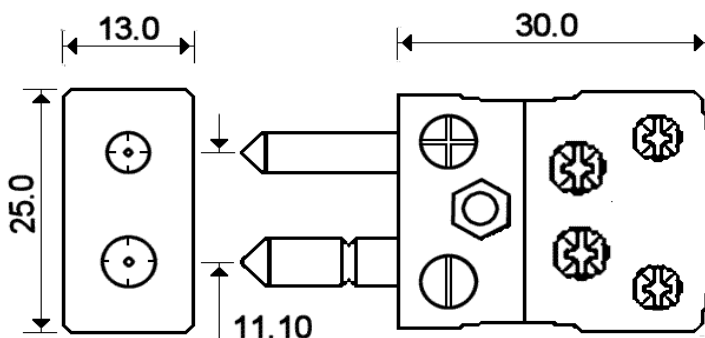

Standard Quick Wire Plug