


Miniature Quick Wire plug


Types K, J, T
(ANSI Colour Code)

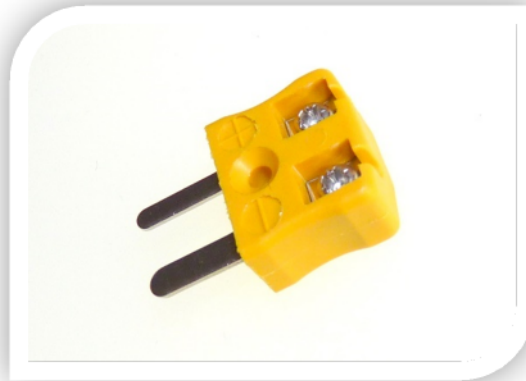

- These quick connect versions allow rapid termination
- Miniature connector with flat plug pins
- Easy 'jab-in' connection for rapid termination, Just push-in wire & tighten screw
- Contacts are polarised to prevent incorrect connection
- Available in Thermocouple types K, J, T
- For Types K, J, T contacts are made from true Thermocouple alloys
- Colour coded in accordance with ANSI specification
- Maximum continuous temperature 220 deg°C

T/C Type	Colour Code (ANSI)	+Positive Contact (alloy type)	-Negative Contact (alloy type)	Manufacturer's Part Number	Rapid Order Code
K	Yellow	+Nickel Chromium	-Nickel Alloy	XE-1141-001	61-3055
J	Black	+Iron	-Copper Nickel	XE-9071-001	61-3056
T	Blue	+Copper	-Copper Nickel	XE-1231-001	61-3057

Schematic Drawing

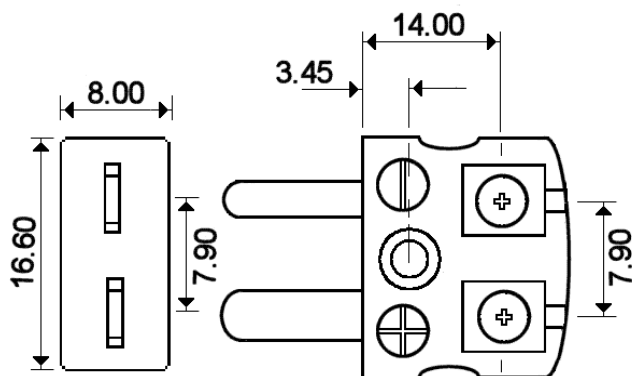

Quick-Wire Miniature Plug

Miniature Quick Wire plug

Types K, J, T
(ANSI Colour Code)

