


### Fine Wire Exposed Junction Thermocouple – PFA insulated

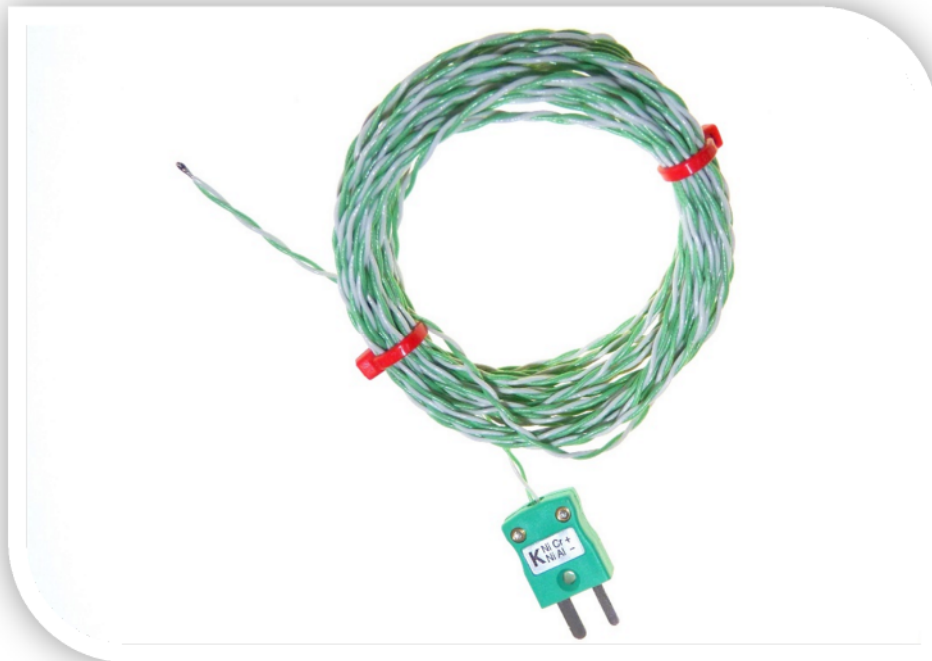

- Thermocouple types K & T to IEC 584
- Fast response, welded exposed junction
- 5 metre long Teflon® PFA insulated twin-twisted lead
- Durable construction with choice of conductor size, 1/0.315mm solid or 7/0.2mm stranded
- Miniature plug termination
- Temperature range –75°C to +250°C
- Ideal for test & development applications

T/C Type	Conductors	Length (mtr)	Miniature Plug	Manufacturer's Part Number	Rapid Part Number
K	1/0.315 Solid	5	Yes	XE-3530-001	<b>61-3200</b>
K	7/0.2 Stranded	5	Yes	XE-3531-001	<b>61-3201</b>
T	1/0.315 Solid	5	Yes	XE-3532-001	<b>61-3202</b>
T	7/0.2 Stranded	5	Yes	XE-3533-001	<b>61-3203</b>