





### Thermocouple Extension & Compensating Cable

PVC Insulated Flat Pair

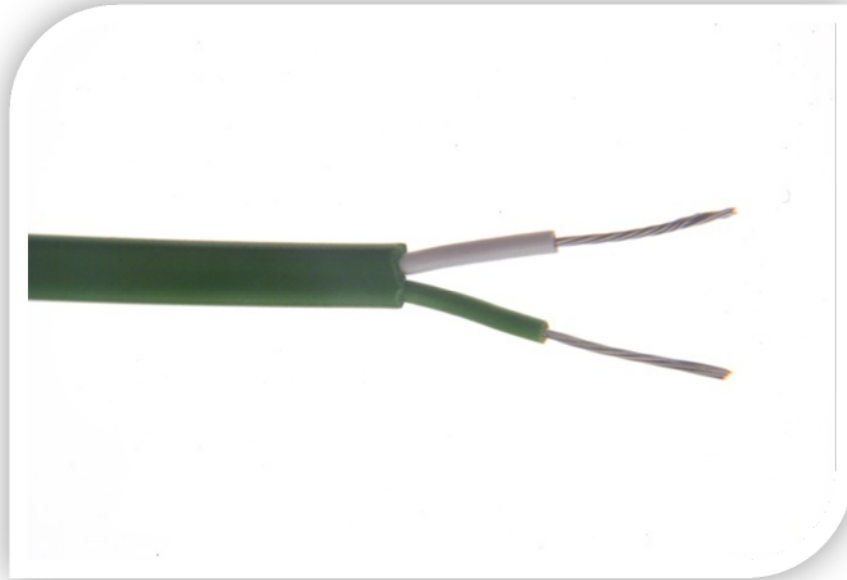

- PVC insulated flat pair construction
- Conductors laid flat PVC insulated with overall PVC sheath
- All round general purpose cable, both waterproof and very flexible
- Thermocouple extension types for K, J
- Compensating types VX (KCB) for types K & R/S Thermocouples respectively
- Stranded conductors available, either 7/0.2mm
- Available in 100 metre lengths
- Tolerance Class 2
- Insulation rating -10°C to 105°C
- Colour code (cores & jacket) to IEC-584-3

<u>Calibration Type</u>	<u>No. of Strands</u>	<u>Colour</u>	<u>Product Code</u>	<u>Manufacturer's Part Number</u>	<u>Rapid Part Number</u>
K	7/0.2 mm		100M - K 7/0.2 PVC F/P IEC	XE-2100-100	<b>61-3231</b>
J	7/0.2 mm		100M - J 7/0.2 PVC F/P IEC	XE-2200-100	<b>61-3232</b>
VX (KCB)	7/0.2 mm		100M - VX 7/0.2 PVC F/P IEC	XE-2550-100	<b>61-3233</b>