



SOCKET & RELAY MODULES

10FF-2Z-C3 DIN Rail Socket

10FF-2Z-C3 Socket



Approved by:




Socket Characteristics

| | |
|---------------------------|--------------------------------|
| Ambient Temperature | -40°C to +70°C |
| Voltage Rating | 250VAC |
| Current Rating | 10A per pole |
| DIN Protection rating | IP20 (DIN40050) |
| Construction material | PA66+GF VO (UL) |
| Spring Contact material | QSn6.5-0.1 |
| Retainer | 10FF-TEC |
| White plastic tag | Non available |
| Modules | Non available |
| Terminal torque | 0.6Nm |
| Wire strip length | 7mm |
| Relay Applications | HF10FH |
| Dielectric Strength (min) | 2000VAC |
| Max wire range | 1 x 4 / 2 x 2.5mm ² |

Dimensions, Socket Terminal Layout and Wiring Diagram

(Units in mm)

Outline Dimensions

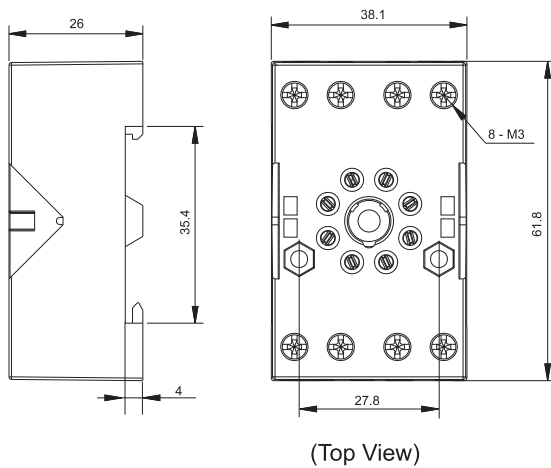

Wiring Diagram

