 




www.eachine.com



EACHINE
TX-D4
 camera
 INSTRUCTION MANUAL

TX04 Parameter

Specification

Frequency: 5.8G
 Channel: 40CH
 Transmitting Power: 25mW
 Working Voltage: 2.5V-5.5V
 Working Current: 255—365mA

Definition: 1000TVL M7 Lens
 Wide Angle Lens: 120°FOV H170°


System: PAL

Size: 17.5*17*14mm

Weight: 4g

Support the auto-save function when power off.

Frequency Control: short press to switch the frequency points, long press(≥2S) to switch the frequency bands.

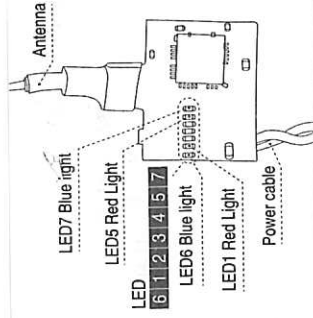

LED Indicator

| Red Light (long light) | |
|------------------------|-------|
| LED1 | LED3 |
| Band1 | Band3 |
| LED4 | LED5 |
| Band4 | Band5 |

| LED6 Blue light | |
|-----------------|---------------|
| CH1 | CH3 |
| Long light | Flash 3 times |
| CH4 | |
| Flash 4 times | |

| LED7 Blue light | |
|-----------------|---------------|
| CH5 | CH7 |
| Long light | Flash 7 times |
| CH8 | |
| Flash 8 times | |

Frequency Table

| | CH1 | CH2 | CH3 | CH4 | CH5 | CH6 | CH7 | CH8 |
|--------|------|------|------|------|------|------|------|------|
| Band 1 | 5865 | 5845 | 5825 | 5805 | 5785 | 5765 | 5745 | 5725 |
| Band 2 | 5733 | 5752 | 5771 | 5790 | 5809 | 5828 | 5847 | 5866 |
| Band 3 | 5705 | 5685 | 5665 | 5645 | 5685 | 5905 | 5925 | 5945 |
| Band 4 | 5740 | 5760 | 5780 | 5800 | 5820 | 5840 | 5860 | 5880 |
| Band 5 | 5658 | 5695 | 5732 | 5769 | 5806 | 5843 | 5880 | 5917 |