


RoHS COMPLIANT

SPECIFICATIONS:

1. RATING: 11V AC 1A MAX
OR 12V DC 2A MAX.
2. INSULATION RESISTANCE:
50M OHM MIN AT 500V DC.
3. DIELECTRIC STRENGTH:
500V AC / 1 MINUTE.

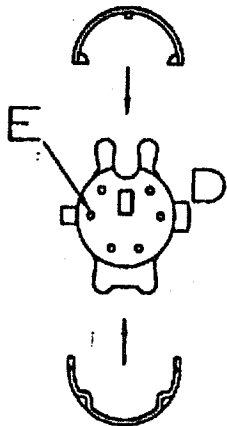

	7.0 ϕ BACK SHELL
	6.0 ϕ BACK SHELL
X	5.0 ϕ BACK SHELL (STANDARD)
	COVER DIM.

TABLE A

MATERIAL:
A. COVER: PE+2L
B. SHELL: ABS
C. METAL SHIELD:
BRASS NICKEL PLATED
D. HOUSING: NYLON66+CF
E. CONTACT:
BRASS SILVER PLATED