

SPECIFICATIONS

Current Rating: 3 Amp

Insulation Resistance: 1000M Ω Min

Dielectric Withstanding: 600V AC/DC

Contact Resistance: 20m Ω Max.

Operating Temperature: -40 $^{\circ}$ c to +105 $^{\circ}$ c

MATERIALS


 
Contact Material: Phosphor Bronze

Insulation Material: Polyester, UL 94V-0
P.B.T

Contact Plating: Full Gold, Full Tin, Selective Plated

Standard: Gold Flash all Over Nickel

All materials must be RoHS compliant.

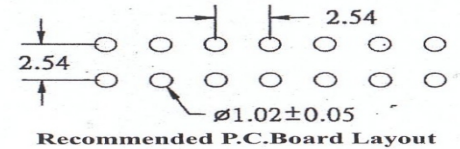

Datenblatt passend für den Artikel

10120828 / 10120829