


Pitch: 3.5mm
 Rated voltage/current: 300V/10A
 Operation temperatures: -40°C to +105°C
 Withstanding voltage: AC1500V/min.
 Insulation resistance: 5000MΩ/DC1000V
 Wire range: 24 to 18AWG, 1.0mm²
 Max. torque value: 2.04kgf·cm



Pitch range in mm			Nominal dimensions range in mm				
6	Over 6 to 10	Over 10 to 24	30	Over 30 to 60	Over 60 to 100	Over 100 to 150	Over 150
±0.10	±0.15	±0.25	±0.2	±0.3	±0.5	±0.7	±1.0

Order code	Poles
21-3000	2
21-3001	3
21-3098	5

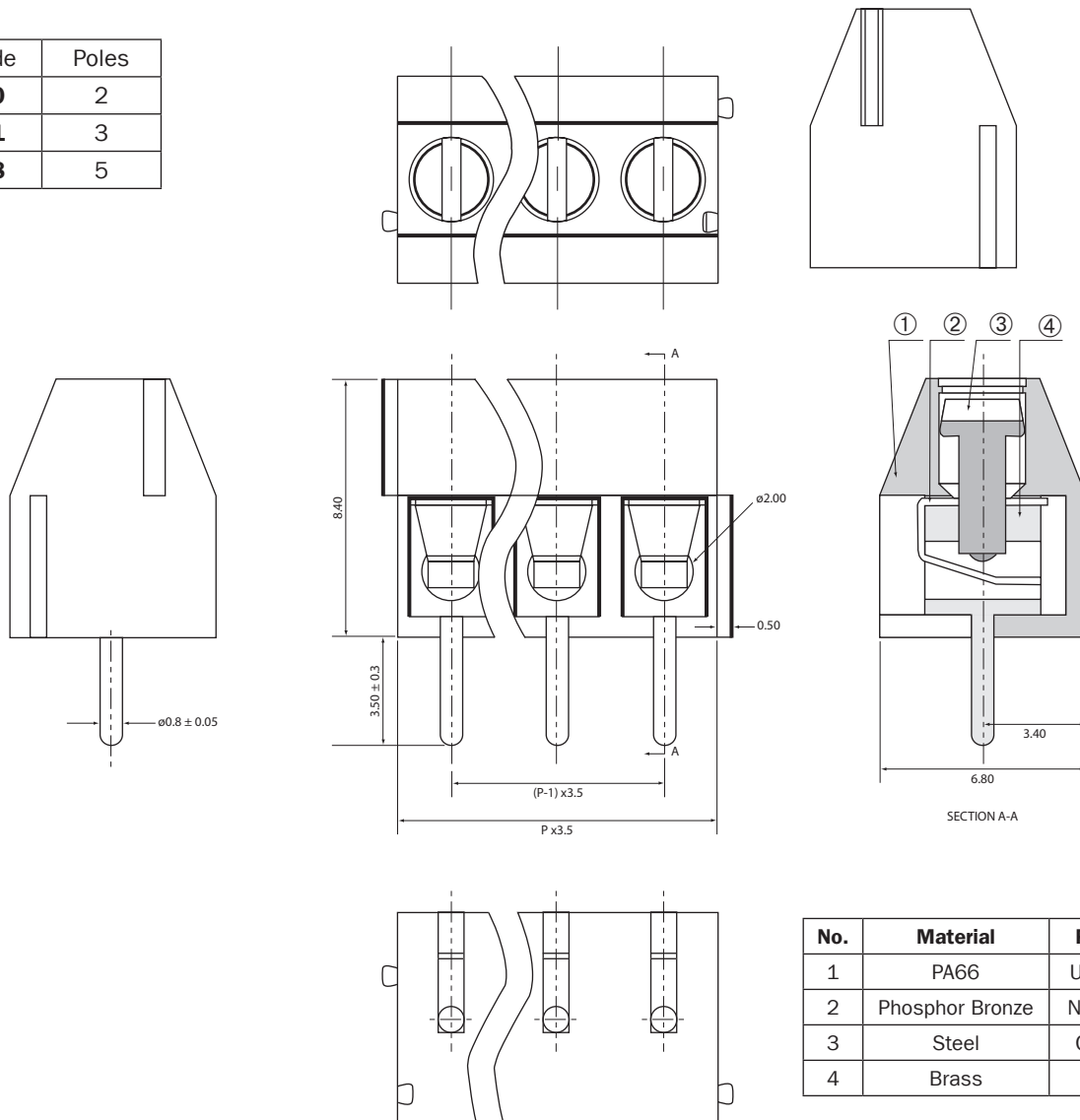

No.	Material	Plating
1	PA66	UL94V-0
2	Phosphor Bronze	Ni plated
3	Steel	Cr ³⁺ Zn
4	Brass	SnCe