

UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 5VDC 10.5 WATT

SW4479B



Features:

- United Kingdom Fixed AC Head
- 1 Year Warranty
- Level VI Efficiency
- CE Approved

Description:

The Stontronics Range of Class II 10.5 watt AC/DC United Kingdom plug-in power supplies provide 10.5 watts of continuous power in a compact fixed wall plug enclosure suitable for use in many general power applications.

Specification	
RS Stock Number	SW4479B
Input Voltage Range	90-264Vac
Input Frequency Range	50-60Hz
Input Current Rated	0.5A max
Output Voltage Rating	5V+
Output Current Range	2.1A
Output Min Current	0.0A
Output Connection Type	USB Socket
Total Output Regulation	+/- 5%
Line and Load Regulation	+/- 5%
Ripple & Noise	120mVp-p
Efficiency	79.04%
Over Voltage Protection	The output voltage shall be clamped by internal protection.
Over Load Protection	Auto-recovery
Operating Temperature	0 to 40°C
Storage Temperature	-20 to +60°C
Operating Humidity	10 to 90%
Storage Humidity	10 to 90%
Hi-Pot	3000VAC 10mA 1min
Leakage Current	0.25mA max
Safety Standard	EN60950-1, Declared& CE Mark
EMI Standard	FCC part 15: Class B ,EN55022:2006+A1:2007, Class B, GB9254-2008, GB17625.1-2003
MTBF	30K Hours
Size mm max.	49.14(L) x 43.14(W) x 34.5(H)
Weight	60g
Regulator Type	Switched Mode Power Supply

General Note


TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics | Stontronics Ltd
Chancerygate Business Centre, Cradock Road, Reading RG2 0AH, UK
t: +44 (0) 118 931 1199

UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 5VDC 10.5 WATT

SW4479B

Diagrams

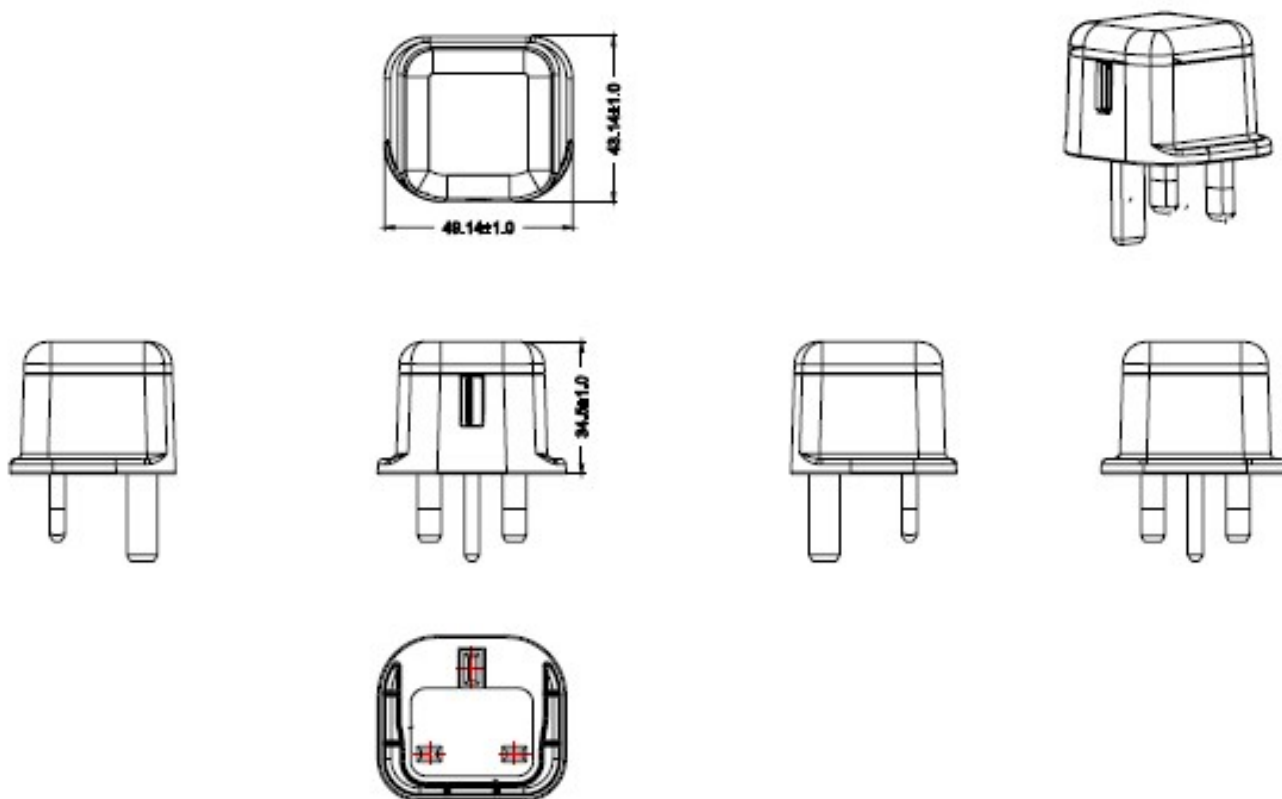

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.