

# Laser Line LL 200V

Product no.: FT91001699N



## Benefits

- › The Constant flow control (CFC) guarantees a automatical air flow regulation independent of the filter pollution rate.
- › Efficiency test via USB port
- › Acoustical and optical filter alarm
- › Low noise level
- › Pre-filter 0,5 -2,5 m<sup>2</sup>


For this purpose, we recommend:



Solder fume extractors



Soldering irons

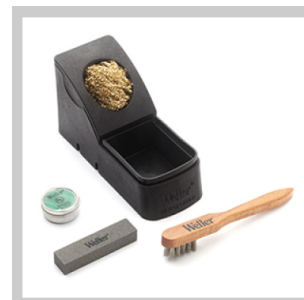

Cleaning



Pre-heating plates



Technical Data

Dimensions L x W x H (mm)	320 x 320 x 700
Dimensions L x W x H (inches)	12,59 x 12,59 x 27,55
Weight (approx.) in kg	---
Voltage	230 V, 50/60 Hz
Power	200 VA
Noise level (distance 1 m) dB(A)	< 52 dB (A)
Max. vacuum	3800 Pa
Capacity m³/h	---
Pre-filter	---
Compact filter	---
Max. capacity	---
RS232 interface (remote control)	All system functions can be operated and remotely monitored via the RS232 port
USB port	---
WX-compatible	---

Owning the bench



PROFESSIONAL



FILTRATION



EREM



XCELITE