

PROSAFE LED FLOATING LANTERN

UNILITE  
PS-L2



5  
HOURS  
RUNTIME

160  
METRE  
BEAM RANGE

200  
LUMENS  
OUTPUT

IP56  
DUST+WATER  
RESISTANCE

- » 200 Lumen White Seoul LED
- » Industrial strength copolymer housing
- » Robust and weatherproof
- » Floats beam upright in water
- » Optical Beamaster lens for beam penetration
- » Ultra tough polycarbonate reflector
- » Rubber Moulded push micro switch
- » High-vis yellow for added safety
- » Contoured easy grip handle

**BATTERY** 1 x 6v PJ996 Lantern battery (not included)  
**WEIGHT** 230g (with battery)  
**DIMENSION** 175 x 105mm



BEAMASTER  
LENS




BEAMASTER LENS TECHNOLOGY



MOULDED RUBBER SWITCH



OPTIONAL ACCESSORY

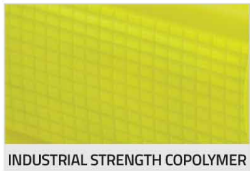

INDUSTRIAL STRENGTH COPOLYMER