


V.403F High capacity belt sander - 20 x 520 mm

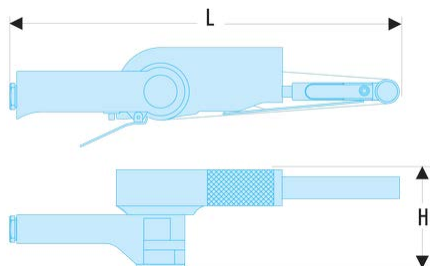

Description:

- Efficient and durable high speed motor delivering 16000 RPM.
- Handle rotates enabling the operator to always have the best grip.
- Easy and fast changing of belts with the quick change arm.
- Feather teasing trigger for great control.
- Starter pack with tool delivered with 3 abrasives: 2 x P120 and 1 x P80.
- Long and Narrow 20 mm arm to get in the most confined spaces.
- Free speed 3500 tr/min.
- Spindle size 5/8"-11.
- Working pressure 6,2 bar.
- Average air consumption 113 l/min.
- Air inlet 1/4".
- Minimum hose diameter 10 mm - 3/8".
- Vibration <math><250\text{ m/s}^2\text{/a}</math>.
- Vibration 0,57 m/s²/K.
- Sound pressure 86,20 dB(A).
- Sound power 97,16 dB(A).
- Available as accessories:
 - 80 grit belt 20 x 500 mm: V.403A1 (minimum ordering quantity: 10).
 - 120 grit belt 20 x 500 mm: V.403A2 (minimum ordering quantity: 10).

A [mm]: 360

E [mm]: 95

H [mm]: 93

L [mm]: 350

[kg]: 1,150