




ISOLATING TRANSFORMER

POWER : 1.5VA
 INPUT VOLTAGE : 230V
 FREQUENCY : 50/60Hz
 NOMINAL OUTPUT VOLTAGE : 2x24V


INHERENTLY SHORT CIRCUIT PROOF TRANSFORMER
 IPOO
 UL94V0
 OPERATING TEMPERATURE : -25°C to 70°C
 STORAGE TEMPERATURE : -25°C to 85°C
 INSULATION CLASS (IEC85) : B
 INHERENT PROTECTION

STANDARDS :
 UL506 (File E111078)
 CSA 22-2 (File E111078)
 CE

CONFORM TO :
 EN61558-1
 EN61558-2-4

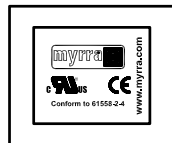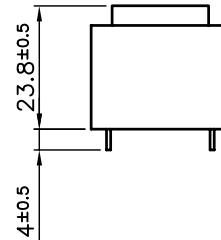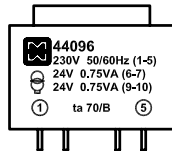

44096 230V 50/60Hz (1-5) 24V 0.75VA (6-7) 24V 0.75VA (9-10) ① ta 70/B ⑤	 Conform to 61558-2-4 www.myrra.com	N°23
--	---	------

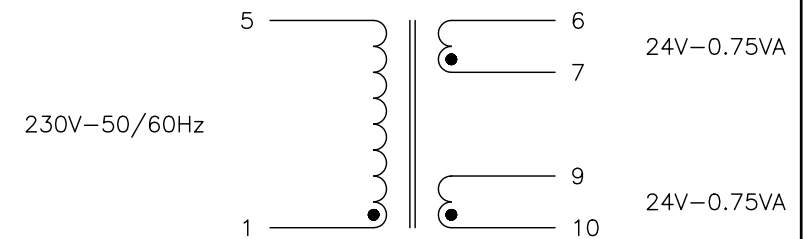

Finition:		Tolérance générale:	
Finition:		General tolerance:	
Ech: 1:1	Matière:		
	Material:		
Dessiné par: ROUSSEL.Ch	Date: 26/05/2004	Visa:	J.P.M.

D					
C					
B					
A					
Rev	Date	Modification	Dessiné	Visa	

DATA SHEET 44096
EI 30x12.5

	22 Allée du Clos des Charmes Z.A. Les Portes de la Forêt 77090 COLLEGIEN Tel : 01-60-37-55-55 Fax : 01-60-17-12-00	DS44096
--	--	---------