



INSTRUCTIONS FOR:

# CREEPER 40" WITH STEEL FRAME, 6 WHEELS & ADJUSTABLE HEADREST DELUXE AMERICAN STYLE

MODEL NO: **SCR74.V2**

Thank you for purchasing a Sealey product. Manufactured to a high standard, this product will, if used according to these instructions, and properly maintained, give you years of trouble free performance.



**IMPORTANT: PLEASE READ THESE INSTRUCTIONS CAREFULLY. NOTE THE SAFE OPERATIONAL REQUIREMENTS, WARNINGS & CAUTIONS. USE THE PRODUCT CORRECTLY AND WITH CARE FOR THE PURPOSE FOR WHICH IT IS INTENDED. FAILURE TO DO SO MAY CAUSE DAMAGE AND/OR PERSONAL INJURY AND WILL INVALIDATE THE WARRANTY. KEEP THESE INSTRUCTIONS SAFE FOR FUTURE USE.**

## 1. SAFETY

- WARNING!** *Ensure Health & Safety, local authority, and general workshop practice regulations are adhered to when using this creeper.*
- ✓ Locate creeper in a suitable working area.
- WARNING!** Use creeper on level and solid ground, preferably concrete.
- ✓ Keep the creeper clean and tidy in accordance with good workshop practice.
- x **DO NOT** use the creeper for any purpose other than that for which it is designed.
- x **DO NOT** stand on the creeper.
- x **DO NOT** get the creeper wet or use in damp or wet locations or areas where there is condensation.
- x **DO NOT** clean the creeper with any solvents which may damage the paint surface or padded areas.

## 2. INTRODUCTION


Heavy steel framework with powder coat paint finish. Easy rolling Ø60mm composite castors with ball bearing swivels. Vinyl covered back and headrest. Headrest is adjustable for comfort.

## 3. SPECIFICATION

Model No: ..... **SCR74.V2**  
 Material: ..... Steel  
 Size: (L x W x H): ..... 1020 x 430 x 100mm  
 Wheels: ..... 6

## 4. ASSEMBLY

- 4.1. Screw on headrest assembly. Use two crosshead screws (fig.2.A) to fix hinges to headrest.
- 4.2. Move headrest adjustment stay to position shown in fig.2.C, screw bracket (fig.2.B) onto adjuster assembly.

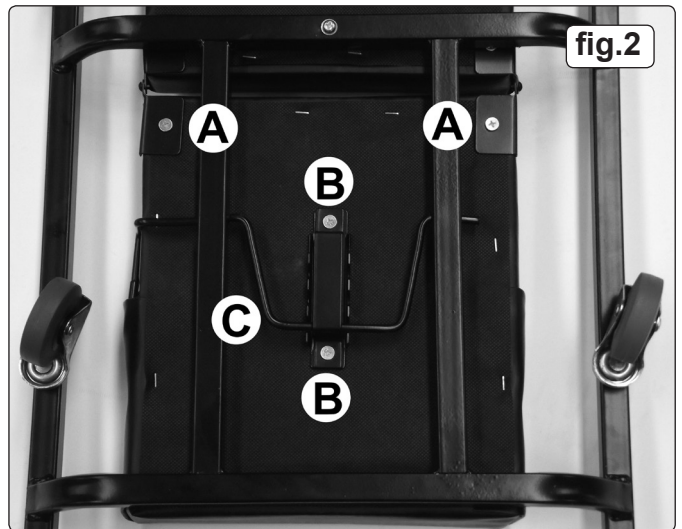

### Environmental Protection



Recycle unwanted materials instead of disposing of them as waste. All tools, accessories and packaging should be sorted, taken to a recycling centre and disposed of in a manner which is compatible with the environment. When the product becomes completely unserviceable and requires disposal, drain off any fluids (if applicable) into approved containers and dispose of the product and the fluids according to local regulations.

Parts support is available for this product. To obtain a parts listing and/or diagram, please log on to [www.sealey.co.uk](http://www.sealey.co.uk), email [sales@sealey.co.uk](mailto:sales@sealey.co.uk) or telephone 01284 757500.

**NOTE:** It is our policy to continually improve products and as such we reserve the right to alter data, specifications and component parts without prior notice.

**IMPORTANT:** No liability is accepted for incorrect use of this product.

**WARRANTY:** Guarantee is 12 months from purchase date, proof of which will be required for any claim.

**INFORMATION:** For a copy of our latest catalogue and promotions call us on 01284 757525 and leave your full name and address, including postcode.



Sole UK Distributor, Sealey Group,  
 Kempson Way, Suffolk Business Park,  
 Bury St. Edmunds, Suffolk,  
 IP32 7AR

01284 757500

01284 703534



[www.sealey.co.uk](http://www.sealey.co.uk)



[sales@sealey.co.uk](mailto:sales@sealey.co.uk)