

# WORKPLACE SAFETY

HELPING TO KEEP PEOPLE SAFE  
IN THE WORKPLACE



**Rapid**


helping you make it  
**[www.rapidonline.com](http://www.rapidonline.com)**

Rapid part of the **CONRAD** Group

live chat available at [www.rapidonline.com](http://www.rapidonline.com)  
[sales@rapidonline.com](mailto:sales@rapidonline.com)



**ONRAD**

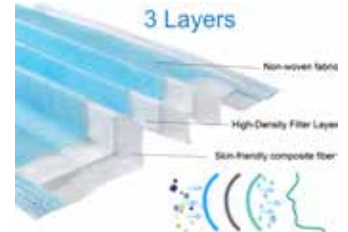

Non Sterile

## Medical Surgical Face Mask Type I 3 Layer

A non-sterile, disposable, 3-layer face mask with elastic ear straps.

- BFE more than 95%
- Material: 3-ply, PA + TE: 25g PP non-woven, 25g melt-blown non-woven, 25g PP non-woven
- Filter class: without filter
- **CE 34/42/EEC**
- **DIN EN 14683 Type I**
- Weight each: 10g
- Supplied in **boxes of 50**

Order code  
65-3589

**£35.99**

Type IIR

## Medical Face Mask

This surgical face mask has elastic ear-loops and is made from 3-ply fabric. The outer layer and inner layers are made of SSS non-woven fabric and the middle layer has a paper filter. The mask gives protection for medical organizations in the general medical environment.

- Surgical face mask with elastic ear-loop
- Dimensions: 175 x 95mm
- 3-ply fabric
- Outer layer and inner layer are made of SSS non-woven fabric
- Middle layer has paper filter
- Protection for medical organization in the general medical environment
- Performance: **BFE, Delta P** conform to the standards of **EN14683:2019** and **YY/T 0969-2013**
- Certification: **NMPA (China), CE (Europe)**
- European reference standard: **Type IIR**
- Supplied in **boxes of 50**

Order code  
65-3583

**£36.99**



**TopGene**

**Box of 50**



BS-9501L FFP2/KN95

# Particle Filtering Half Mask

These CE marked and fully certificated masks are manufactured to FFP2\* standard, meeting the requirements for use across the EU. They are listed as an approved respirator model, from an approved respirator manufacturer, by the Centers for Disease Control and Prevention (CDC).

The World Health Organisation (WHO) recommends the use of FFP2 masks for healthcare workers and the NHS also state that FFP2 masks provide protection of the respiratory system. They are recommended for use by the WHO during outbreaks of SARS, Avian Flu and Coronavirus.

These particle-filtering half -masks give 360° protection and have a 4-layer filtration system that guarantees that 95% of droplets are trapped within the filter. An embedded, adjustable nose clip allows the mask to be put on and adjusted easily to your face shape. It also has comfortable elastic ear bands and a skin-friendly breathable fabric to ensure maximum comfort when wearing for long periods of time. The mask incorporates 2 layers of Level 95 melt-blown fabric to protect from bacteria, germs, dust, fog and formaldehyde.

\* FFP stands for 'Filtering Face Piece' and is followed by a number that increases with the level of protection, thus, FFP2 masks provide more protection than FFP1 masks.

- Supplied **singly**



**Supplied  
singly**



**BOLISI™**

Model No.	BS-9501L FFP2 NR
Colour	White
Size (folded)	16 x 10.5cm
Layers	4
Weight	8.2g
Ear-loop length	2 pieces 14.5cm
Nose clip	Plastic (hidden) inside with sponge
Nose clip size	8.5cm
Assembly method	Ultra-sonic
Material	Non-woven fabric, melt-blown fabric
Standard	<b>GB/T 32610-2016</b>
CE Standard	<b>EN149:2001+A1:2009/ PPE module B+C2</b>
Class/NB	<b>FFP2 NR/CCQS NB2834</b>
Filtration	95% up
Shelf life	3 years in a dry and cool environment

## HOW TO USE

- Unfold the mask, place the mask on your face then put an ear loop around each ear
- Press the nose clip lightly to make it bend to your face shape
- Pull the bottom of the mask down to cover your whole chin

## PRECAUTIONS

- This product is disposable and must not be used after cleaning or after getting wet
- The mask should be destroyed or cut / broken after usage to prevent re-use
- Do not wear the mask if you have difficulty breathing, or if the package is open with the mask exposed
- Not recommended for children under 3 years of age

Order code  
65-3577

**£5.99**

**Rapid**

helping you make it  
**www.rapidonline.com**

Rapid part of the **CONRAD** Group



live chat available at [www.rapidonline.com](http://www.rapidonline.com)  
[sales@rapidonline.com](mailto:sales@rapidonline.com)



**Rapid**

FS-01

## Face Shield

The Rapid FS-01 face shield provides effective eye and face protection from direct droplet splashes.

- Perfect visibility
- Double-sided anti-fog surface
- Very low weight - only 45g
- Soft forehead foam
- Remove protective film from transparent visor before use

Order code  
65-3579

**£1.99**



## Virtua AP Classic Line Safety Spectacles with Grey Lens

These 3M Virtua AP Classic Line Safety Spectacles have grey lenses and feature sleek unisex styling designed to appeal to both the male and female wearer.

The wrap-around design features an integral side-shield for improved safety and greater protection, while the optical class 1 lens allows for high optical clarity and extended wear time..

- Grey lens
- 90% visible light transmittance
- Sleek unisex stylish design
- Integrated brow bar for added protection
- Lightweight (26g) for maximum comfort
- Streamline wrap-around design for excellent coverage and good field of vision
- Strong polycarbonate lenses featuring anti-scratch coating for improved vision and extended durability
- 2C-1.2.3M.1.FT lens marking
- **EN 166:2001 approval**

Order code  
51-7976

**£3.01**

**SEALEY**



SSP65

## Clear Lens Safety Spectacles

Wraparound, clear polycarbonate lenses with tight fitting nylon arms to prevent glasses from slipping.

- Conforms to CE standards - **BS EN 166/F**

Order code  
89-9619

**£3.43**



**Ambersil**

250ml

## IPA Solvent

Ambersil 31713-AA IPA Electronic Cleaning Solvent is an isopropyl alcohol solvent - an internationally approved general purpose, cost effective electronic cleaning solvent. It is ideal for cleaning, degreasing and de-fluxing delicate electronic assemblies and leaves no residue.

Order code  
87-7378

**£5.27**



67% Alcohol

## Hand Sanitising Gel with Lemongrass

Sychem Alco Gel is an alcohol-based hand-sanitiser containing 67% alcohol in the form of a high-level, broad-spectrum antibacterial hand cleanser gel. It is fast-drying on hands and skin, with the added benefit of not leaving a sticky residue after application. It refreshes and cleanses the skin, and is ideal for use in offices, care homes, food services areas, GP surgeries and veterinary practices to name but a few.

- 67% alcohol content
- Lemongrass fragrance
- Supplied in **100ml** and **250ml flip-top bottles**

**100ml** Order code 87-2700 **£2.99**

**250ml** Order code 87-2702 **£4.99**

IPA 170

## Isopropyl Alcohol Cleaning Solvent

A universally recognised electronic cleaning solvent that forms an azeotrope with water, which evaporates more quickly than water for quick and efficient removal of moisture, leaving no residues.

- Ideal for cleaning tape heads, disk drives, photocopier drums, PCBs, optical equipment, lenses, precision instruments and delicate components
- Conforms to **BS1595**, **ASTM D770** and **DIN 53245**
- Supplied in a **400ml aerosol** with extension nozzle, or in a **1 litre tin**

**400ml** Order code 87-1080 **£6.99**

**1L** Order code 87-1082 **£15.82**



- Highly versatile cleaning solvent
- Manufactured using IPA with a minimum purity of 99.7%
- Conforms to **BS 1595**, **ASTM D770** and **DIN 53245**
- Forms an azeotrope with water to assist removal of moisture
- Evaporates after use, leaving no residue
- Drying can be accelerated by wiping or using an air lance
- Suitable for: tape heads, disc drives, photocopier drums, printed circuit boards, optical equipment, lenses, precision instruments, delicate components, etc.
- Supplied in a **250ml bottle**

**Caution:** IPA may affect certain delicate plastics. Always test small, inconspicuous area before general use. Ensure electrical equipment is switched off before cleaning. Allow solvent to evaporate completely before operating the equipment.

[www.rapidonline.com](http://www.rapidonline.com)

## Super Professional Antiviral Disinfectant

This Super Antiviral Disinfectant's powerful formulation kills a range of pathogenic viruses in under 5 minutes.

Its safe formula is suitable for use on most non-porous surfaces and when used as directed, leaves treated surfaces safe for human contact.

- **Effective against Coronavirus**
- Kills 99.99% of germs and viruses
- Cleans and disinfects
- Ready to use
- Contains Alkyl (C12-16) dimethylbenzyl ammonium chloride (ADBAC/BKC (C12-16)) 0.125g/100g



**Effective against Coronavirus**

**750ml** Order code 34-2238 **£4.99**

**5L** Order code 34-2240 **£16.99**

**Rapid**

helping you make it  
[www.rapidonline.com](http://www.rapidonline.com)

Rapid part of the **CONRAD** Group

live chat available at [www.rapidonline.com](http://www.rapidonline.com)  
[sales@rapidonline.com](mailto:sales@rapidonline.com)



Blue 2-ply

## Embossed Paper Roll

Pack of six blue embossed paper, centre-feed, 2-ply, perforated roll wipes.

- Length: 150m; Width: 190mm
- Supplied in a **pack of 6 rolls**

Order code  
84-9992

**£14.91**



Tub of 100

## PC Clene Wipes

Anti-static, lint-free cleaning wipes developed for removing dirt and grime from glass and plastic surfaces of PCs and other computer related equipment..

- Ideal for PC cases, keyboards, VDU screens and filters
- For best results on glass and filters, dry off with Safetiss tissues, order code 87-0930
- Not suitable for mesh type screen filters
- Supplied in **tubs of 100 wipes**

Order code  
87-0198

**£5.45**



Pack of 30

## PSA AR0006474 Ki-Ose 390

The Ki-ose 390 Disinfectant Wipes from PSA are dual use, high efficacy wipes that are ideal for use on both hands and surfaces.

The active ingredient kills 99.99% of most of harmful bacteria, viruses and fungi and is dermatologically tested to be safe for use on unbroken skin and will not harm or damage fabrics, plastic, metals, rubber or other surfaces. The wipes have specially designed and approved for use by flight cabin crews which attests to their effectiveness and safety. The 150 x 200mm non-woven spunless wipes will not tear and are ready to use.

Antiseptic solution for fast hand antiseptis and disinfection of surfaces

Dermatologically tested – safe for use on unbroken skin

Very light floral fragrance

Shelf life 24 months

Active ingredient: 0.2% m/m didecyldimethylammonium chloride n° CAS 7173-51-5


Certifications AMS 1453 – BOEING D6-7127, Airbus CML 14-012



Order code  
87-0180

**£3.20**



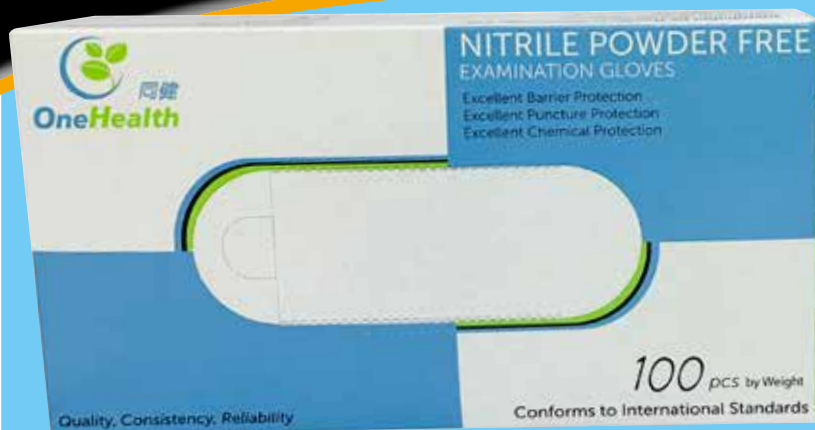

Box of 100

## Disposable Nitrile Powder Free Gloves

Disposable, powder-free Nitrile examination gloves offering excellent barrier protection.

- Latex-free
- Powder-free
- Beaded cuff
- Textured finger tips
- Single use
- Non-sterile
- Ambidextrous
- Puncture resistant
- Chemical resistant
- CE approved



**Small** Order code 65-3710 **£19.99**

**Large** Order code 65-3712 **£19.99**

**Medium** Order code 65-3711 **£19.99**

**XL** Order code 65-3717 **£19.99**



50mm x 33m

## 766i & 767i Hazard Marking Adhesive Tapes



3M 766i & 767i all-purpose soft PVC adhesive tapes offer an economical solution for hazard warning and marking.

The abrasion-resistant and stretchable PVC material is very easy to process and gives a pleasing finish on uneven surfaces..

- Width 50mm
- Thickness 0.125mm
- Supplied on **33m reels**

**3M**



**767i** Order code 51-2071 **£4.26**

**766i** Order code 51-2070 **£4.52**

50mm x 33m

## Black/Yellow Hazard Warning Tape

Hazard warning tape made from heavy-duty plasticised PVC film.

- Coated with an aggressive, white, non-corrosive, pressure-sensitive adhesive
- Highly flexible
- Water and UV resistant
- Good abrasion resistance
- Can be walked on immediately after laying
- 0.14mm thick, 50mm wide
- Supplied on **33m reels**

Order code 87-3020

**£3.99**

**Rapid**

helping you make it  
**www.rapidonline.com**

Rapid part of the **CONRAD** Group

live chat available at [www.rapidonline.com](http://www.rapidonline.com)  
[sales@rapidonline.com](mailto:sales@rapidonline.com)



**magnetoplan®**

## Mobile Acrylic Protective Walls

### Acrylic Hygiene Screens

These magnetoplan acrylic hygiene screens protect you and your customers from viruses and infections by providing effective cough, sneeze and spit protection.

The extra slim countertop shields are made from acrylic 'glass' and offer protection in places like sales counters, reception desks and cash desks. They have a pass-through opening of 250 x 200mm (W x H) enabling the safe exchange of goods and payment.

#### IDEAL FOR:

- ☐ PHARMACIES AND MEDICAL PRACTICES
- ☐ SHOPS
- ☐ PETROL STATIONS
- ☐ BANKS
- ☐ AND MANY OTHER FACE-TO-FACE APPLICATIONS





# Protective Walls

829mm wide x 927mm high

Order code 65-3705 **£74.99**

1029mm wide x 927mm high

Order code 65-3706 **£89.99**

This cost-effective partitioning system provides protection against sneezing, spitting and coughing. The acrylic 'glass' protects against virus infections at sales counters, reception counters and cash desks. The partition has a pass-through space across its entire width enabling the exchange of goods and payment.

- Acrylic surface
- Sturdy aluminium frame
- Colour: light-grey lacquered finish
- T-shaped stand supports made of metal for high stability
- Can be attached to other screens by means of the supplied adapter
- Can be used immediately without the need for tools
- Acrylic screen height: 650mm
- Overall height: 927mm
- Available in 829mm and 1029mm widths



500mm wide x 850mm high

Order code 65-3707 **£54.99**

700mm wide x 850mm high

Order code 65-3708 **£64.99**

850mm wide x 700mm high

Order code 65-3709 **£64.99**



**Rapid**

helping you make it  
**www.rapidonline.com**

Rapid part of the **CONRAD** Group

# WORKPLACE SAFETY

HELPING TO KEEP PEOPLE SAFE  
IN THE WORKPLACE

Clean  Health®


Polyamide 71 x 105 x 78mm

## Hands-Free Door Openers

Everyone touches door handles. They are particularly affected by germs - especially in places with a lot of traffic. These hands-free door openers simply and effectively reduce the transmission possibility of, for example, corona and influenza viruses in all areas, such as companies and public institutions.

These innovative handles allow you to open a door, fitted with a standard handle, by using your forearm, reducing the risk of direct hand contact with any viruses and bacteria present on the door handle. The door openers have an ergonomic shape, are very easy to install and can be fitted to existing handles with diameters from 16 to 24mm as well as oval and angular shapes.

- Open a door using your forearm
- Reduce risk of direct hand contact with viruses and bacteria
- Valuable ally in the fight against COVID-19
- Ergonomic shape
- Easy to install
- Use with handle diameters from 16 to 24mm as well as oval and angular shapes
- Front made from tough glass-fibre reinforced polyamide plastic
- Stainless steel screws and nuts
- Tools required: 3mm hexagonal Allen key (not included)
- Dimensions: 105 x 71 x 78mm
- Available in a range of colours

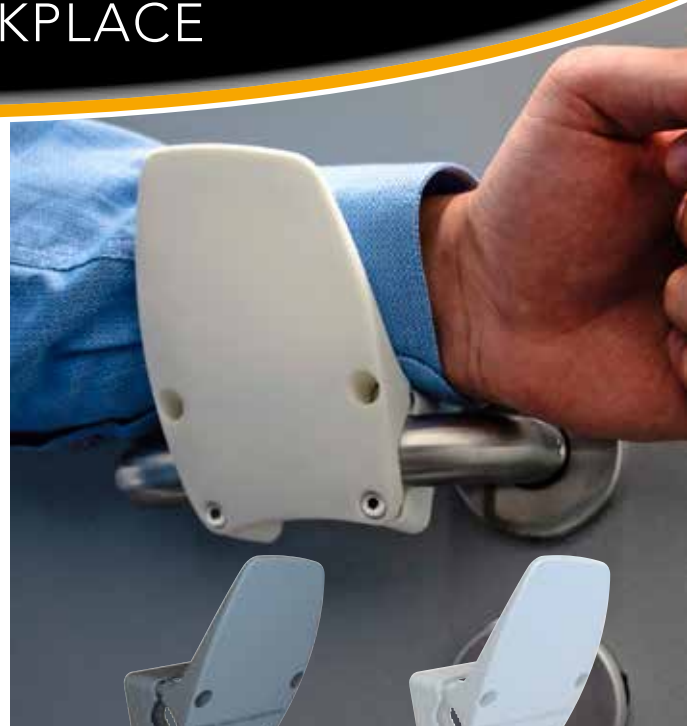

Order code  
65-3713

**£9.99**

Order code  
65-3714

**£9.99**



Order code  
31-0100

**£7.99**

L-Bow Handle

## Hands Free Door Opener

The innovative L-bow handle allows you to open a door, fitted with a standard handle, by using your forearm, reducing the risk of direct hand contact with viruses and bacteria on the door handle. It could prove to be a valuable ally in the fight against COVID-19.



The door opener itself has an ergonomic shape, is very easy to install and can be used for handles with diameters from 19 to 22mm. To disinfect the door opener, simply wipe it with a cloth moistened with ethanol.

- Open a door using your forearm
- Reduce risk of direct hand contact with viruses and bacteria
- Valuable ally in the fight against COVID-19
- Ergonomic shape
- Easy to install
- Use with handle diameters from 19 to 22mm
- Disinfect with a cloth moistened with ethanol
- Standard colour: black

**Rapid**

Live chat available at [www.rapidonline.com](http://www.rapidonline.com)  
Email : [sales@rapidonline.com](mailto:sales@rapidonline.com)

Severalls Lane, Colchester, Essex C04 5JS

E&OE. All content and images are subject to copyright and cannot be reproduced in any form without the express permission of Rapid Electronics Limited. Featured products are currently VAT exempt\*. Prices may vary, see website for up-to-date pricing. For all information regarding Article 13 GDPR, as well as your right to object, please consult [rapidonline.com/privacy](http://rapidonline.com/privacy). For full terms & conditions visit [www.rapidonline.com/terms](http://www.rapidonline.com/terms) M0981 06/20

Rapid part of the **CONRAD** Group

\*Subject to change by the Government



CUSTOMER  
SERVICE  
EXCELLENCE®

