


Flat Profile Communication Cable - 100m

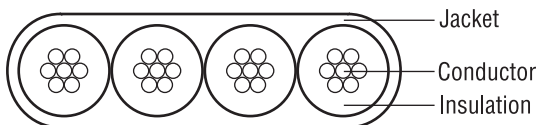

1. CONSTRUCTION			
Item		A.Q.L.	Description
Conductor	NO./mm	0.15	Stranded bare copper
	4/0.15 x7	(+/-0.008)	
Insulation	NO./mm	1.0	Yellow, green, red, black PVC insulation
	4/1.0 PVC	(+/-0.10)	
Shield	NO./mm		—
	—	—	
Jacket	NO./mm	2.50 (+/-0.15)	White PVC jacket
	2.50 x 5.0	5.00 (+/-0.25)	

2. DESIGN	
	

3. CHARACTERISTICS		
Item	Description	Standards
1. Inne-rcond. Res.	20°C, Conductor DC Resistance	< 15.55 Ω/100m
2. Rated Tem.	—	80°C
3. Rated Volatage	—	30V
4. Others	—	—