

TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL 94 V-0 Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

Standard D-Sub Solder Cup:


Insulator:	Glass filled TP, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy Gold Flash over Ni.
Stamped & Formed Pins	Class 3, 100 inserts min.
Contact Plating:	Gold flash over Nickel
Operating Temperature:	-55°C to +85°C
Withstanding voltage:	>1000V Rms to 50 Hz for 1 minute
Current Rating:	5A
Insulator resistance:	>5000MΩ min.

Features:


- Available in sizes 9-15-25-37
- 360° EMI Shielding
- Re-openable



...with Connectors from:
Amphenol

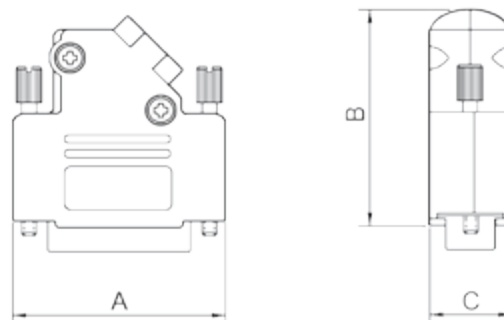

Grommet Sizes D45PK-P:

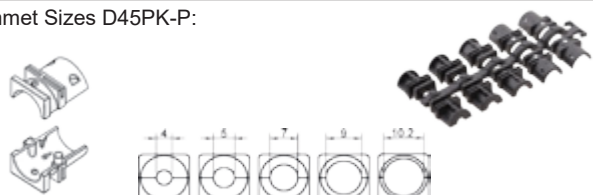

Size D45PK-P	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:**Standard D-Sub Connector Kits**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-5016-01	D45PK-M-09+L717SDE09P
15-way	6355-5016-02	D45PK-M-15+L717SDA15P
25-way	6355-5016-03	D45PK-M-25+L717SDB25P
37-way	6355-5016-04	D45PK-M-37+L717SDC37P

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-5016-11	D45PK-M-09+L77SDE09S
15-way	6355-5016-12	D45PK-M-15+L77SDA15S
25-way	6355-5016-13	D45PK-M-25+L77SDB25S
37-way	6355-5016-14	D45PK-M-37+L77SDC37S



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com