

## TECHNICAL SPECIFICATIONS

**D-Sub Hood:**

|                        |                            |
|------------------------|----------------------------|
| Material:              | UL 94 V-0 Plastic Material |
| Operating Temperature: | -55°C to +110°C            |
| Cable Entry:           | Top                        |
| Thumbscrews:           | UNC 4-40 (Standard)        |
| Cable O.D:             | Up to 11,5mm               |
| Colour:                | Black                      |

**D-Sub Screw Connector:**


|                        |                                                  |
|------------------------|--------------------------------------------------|
| Insulator:             | Glass filled TP, UL94 V-0                        |
| Shell:                 | Steel, Tin Plated                                |
| Contact pins:          | Machined Brass pins<br>15µ" Gold plated over Ni. |
| AWG Wire Size:         | AWG 18                                           |
| Contact Plating:       | Gold flash over Nickel                           |
| Operating Temperature: | -55°C to +85°C                                   |
| Withstanding voltage:  | >1000V Rms to 50 Hz<br>for 1 minute              |
| Current Rating:        | 7.5A                                             |
| Insulator resistance:  | >5000MΩ min.                                     |

**Features:**


- Available in sizes 9-15-25
- Strain relief inserts ensure a secure termination
- Re-openable



...with Connectors from:  
**Amphenol**

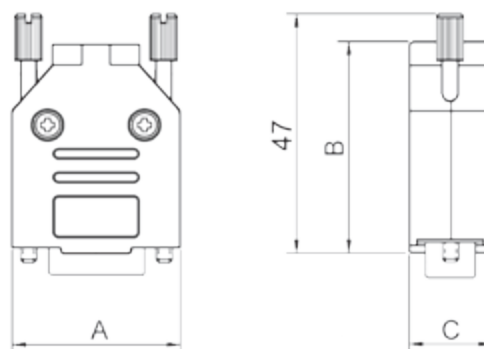

Grommet Sizes DTPK-P:

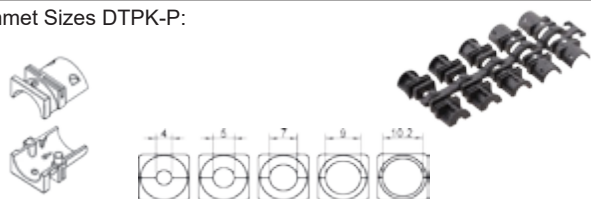

| Size DTPK-P | Dim A | Dim B | Dim C |
|-------------|-------|-------|-------|
| 9-way       | 31,2  | 39,9  | 15,0  |
| 15-way      | 39,5  | 41,5  | 15,0  |
| 25-way      | 53,4  | 48,6  | 15,0  |

**Ordering information:****Screw Connector D-Sub Connector Kits**

| Size:  | P/N - Kitted: | Product Code - MALE Conn. Kit |
|--------|---------------|-------------------------------|
| 9-way  | 6355-5006-01  | DTPK-P-09+L717SDE09PST        |
| 15-way | 6355-5006-02  | DTPK-P-15+L717SDA15PST        |
| 25-way | 6355-5006-03  | DTPK-P-25+L717SDB25PST        |

| Size:  | P/N - Kitted: | Product Code - FEMALE Conn. Kit |
|--------|---------------|---------------------------------|
| 9-way  | 6355-5006-11  | DTPK-P-09+L77SDE09SST           |
| 15-way | 6355-5006-12  | DTPK-P-15+L77SDA15SST           |
| 25-way | 6355-5006-13  | DTPK-P-25+L77SDB25SST           |



**Encitech AB**  
Rörkullsvägen 4  
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90  
Fax: +46-(0)35-15 13 99

**www.encitech.com**