
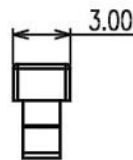
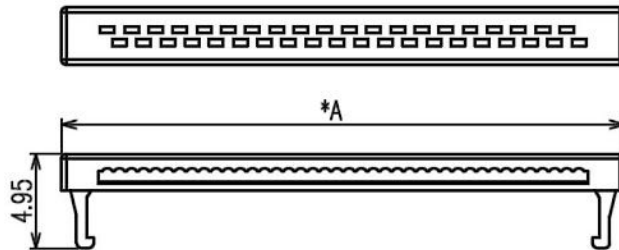


Arti el-Nr.: 2103796

Bez.: IDC Pfosten-Verbinder zweireihig, Raster 1,27mm, 16-polig

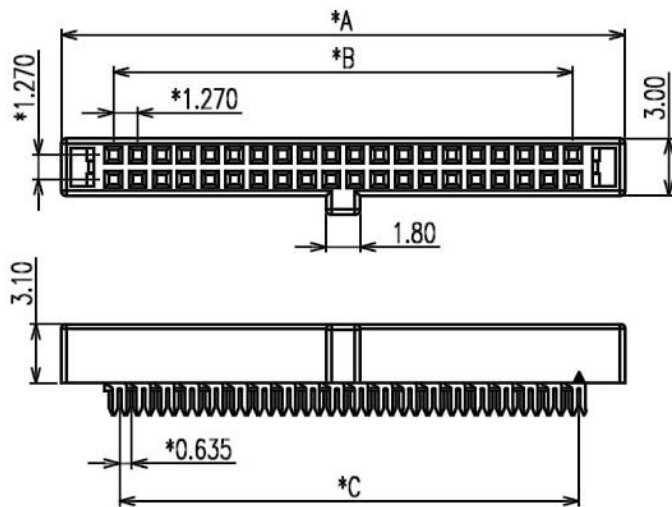

Specifications:

Current Rating: 0.5 Amp

Contact resistance: 30m Ohm Max.

Insulator resistance: 1000M ohm min.

Operating Temperature Range: -40°~+105°C


Flat Ribbon Cable With 0.635mm Pitch.

Material And Finish

Insulator: PBT&Glass-fiber reinforced UL94V-0

Insulator Color: Black

Contact: Phosphor Bronze

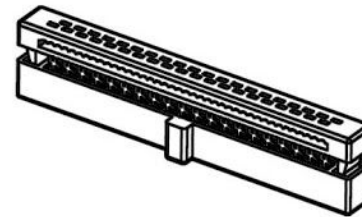

No. of Positions:

No.	A	B	C	No.	A	B	C	No.	A	B	C
06	8.01	2.54	2.54	22	18.17	12.70	12.70	40	29.60	24.13	24.13
08	9.28	3.81	3.81	24	19.44	13.97	13.97	44	32.14	26.67	26.67
10	10.55	5.08	5.08	26	20.71	15.24	15.24	50	35.95	30.48	30.48
12	11.82	6.35	6.35	30	23.25	17.78	17.78	60	42.30	36.83	36.83
14	13.09	7.62	7.62	32	24.52	19.05	19.05	64	44.84	39.37	39.37
16	14.36	8.89	8.89	34	25.79	20.32	20.32	68	47.38	41.91	41.91
20	16.90	11.43	11.43	36	27.06	21.59	21.59	80	55.00	49.53	49.53

RoHS COMPLIANT

www.bkl-electronic.de

Die Angaben auf unseren Datenblättern erfolgen nach bestem Wissen. Sie sind nur ein unverbindlicher Hinweis und dienen als Anhaltspunkt für Planungen.

Sie befreien den Anwender nicht von eigener Prüfung der von uns gelieferten Produkte auf ihre Eignung für die beabsichtigten Anwendungszwecke.

Änderungen behalten wir uns vor, falls neue Erkenntnisse dies erforderlich machen. Ausführungen können variieren.

Sollten Sie ein Muster benötigen, kontaktieren Sie uns bitte.

BKL-Electronic Kreimendahl GmbH · Märkenstück 14 · 58509 Lüdenscheid

Tel: +49 (0)2351-3621-0 · Fax: +49 (0)2351-3621-29 · info@bkl-electronic.de

