

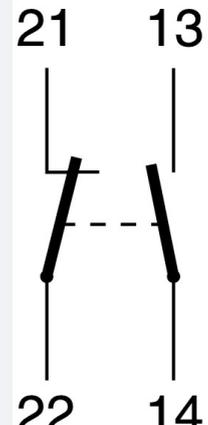


**Auxiliary contact, for PLS, postal Code, PKNM, ZP-A40...-ASA...IHK...WHK, Z-MS, 1N/O+1N/C, 0.5HP**

**Part no. ZP-IHK**  
**Catalog No. 286052**

**EL-Nummer (Norway) 1609488**

### Delivery program

Basic function		Accessories for combined residual-current/power circuit-breakers Accessories for miniature circuit-breaker
Basic function accessories		Auxiliary contacts
Application		Switchgear for industrial and advanced commercial applications
Product range		Accessory
Side mounting		for fitting on left to: LS, FI/LS
Contact sequence		

### Technical data

#### Design verification as per IEC/EN 61439

Technical data for design verification		
Operating ambient temperature min.	°C	-5
Operating ambient temperature max.	°C	40

#### Technical data ETIM 7.0

Devices for distribution board-/surface mounting (EG000062) / Auxiliary device for distribution board devices (EC001286)		
Electric engineering, automation, process control engineering / Electrical installation, device / Breaker switch component / Auxiliary contact unit for distribution board (ec@ss10.0.1-27-14-35-02 [AKE327013])		
Device fitting		Universal
Additional equipment		Auxiliary switch
Attached at delivery		No
Assembly width (TE)		0.5
Number of contacts as normally open contact		1
Number of contacts as normally closed contact		1
Number of contacts as change-over contact		0
Number of fault-signal switches		0
Rated switch current	A	3
Rated voltage	V	230
Voltage type for actuating		AC
With auto test for earth leakage function		No

Suitable for max. number of poles main contact unit (total)		2
Suitable for max. current main contact unit	A	6

## Dimensions

