

Laboratory & Measuring Connectors Alligator Clips

Blank with 4 mm Socket not insulated
and screw



SPECIFICATION:



Operating Voltage (Max.):	60 Vdc
Operating Current (Nom.):	10 A
Operating Temperature:	-20°C to 90°C
Contact Resistance (Max.):	5 mΩ

MATERIAL:

Material (Terminal):	steel, nickel plated
Material (Contact Area):	steel, nickel plated

HANDLING:

Terminal:	plug / screw
Packaging:	bulk
PU:	100 piece(s)

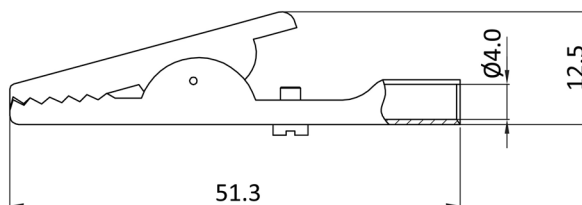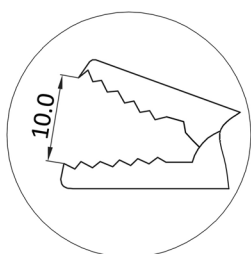

Order Information

Identifier:

AK40

Colour:

M

Crocodile clamp with 4.0 socket w/o insulation

blank