

D-Sub High Density, Crimp

Crimp Contacts for Female Connectors HD



SPECIFICATION:

Current rating: 3 A
Contact resistance: 13 mΩ max.
Dielectric voltage: 500 V AC
Wire range: AWG24-26
Insulation outer diameter: 1.5 mm max.
Operation temperature: -55 °C to +105 °C

MATERIAL:

Contact: Brass

FINISH:

Contact: Gold Flash


HANDLING:

Packing: Reel with 5K, otherwise 100 pcs and multiple cut

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

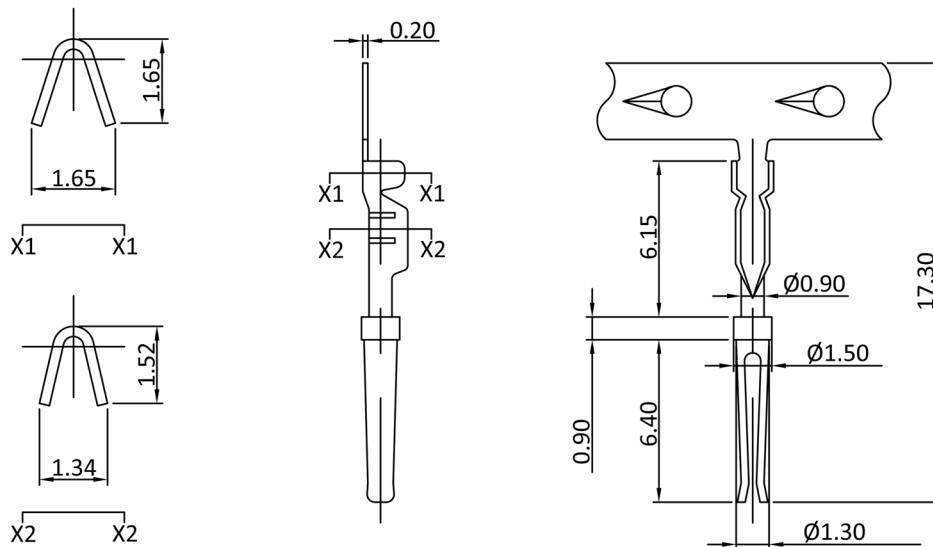

Order-Information

Identifier:

BHCR

Female contacts cimp

Packing unit:

#

empty: 100 pcs cut

10K: Reel with 10.000 pcs.