

Female Header Pitch 2.54 mm straight

Double row, height 5.7 mm



SPECIFICATION:

Current rating: 3 A
Insulation resistance: 1000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 1000 V AC
Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
Contacts: Copper alloy

FINISH:

Contacts: Gold Flash




 

HANDLING:

Processing: Wave soldering
Packing: Tube

TOLERANCE:

.X ± 0.25
.XX ± 0.20

RoHS
COMPLIANT

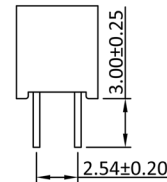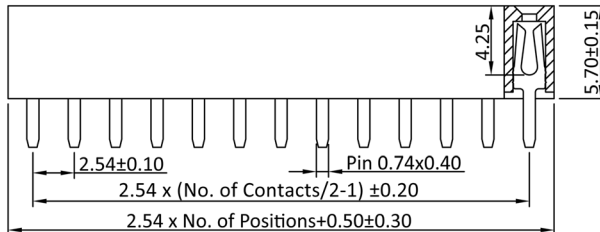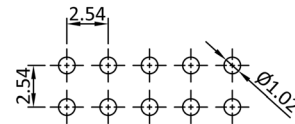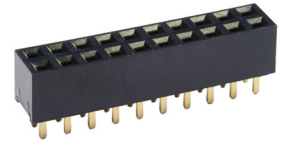

Order-Information

Identifier:	No. of contacts:	Version:	Plastic Height:
BL	#	G	5
Female Header Pitch 2.54 mm double row straight	2/2: 2 x 2 3/2: 2 x 3 4/2: 2 x 4 : 40/2: 2 x 40	G: Straight	5: 5.7 mm