

D-Sub PCB angled US Norm

Female Connectors with Threaded Bolt
UNC 4/40



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 1.5 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Insulator: PBT black UL94V-0
 Shell: Steel
 Pins: Brass

FINISH:



Contacts: Selective gold flash
 Shell: Nickel plated

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ± 0.38
 .XX ± 0.25

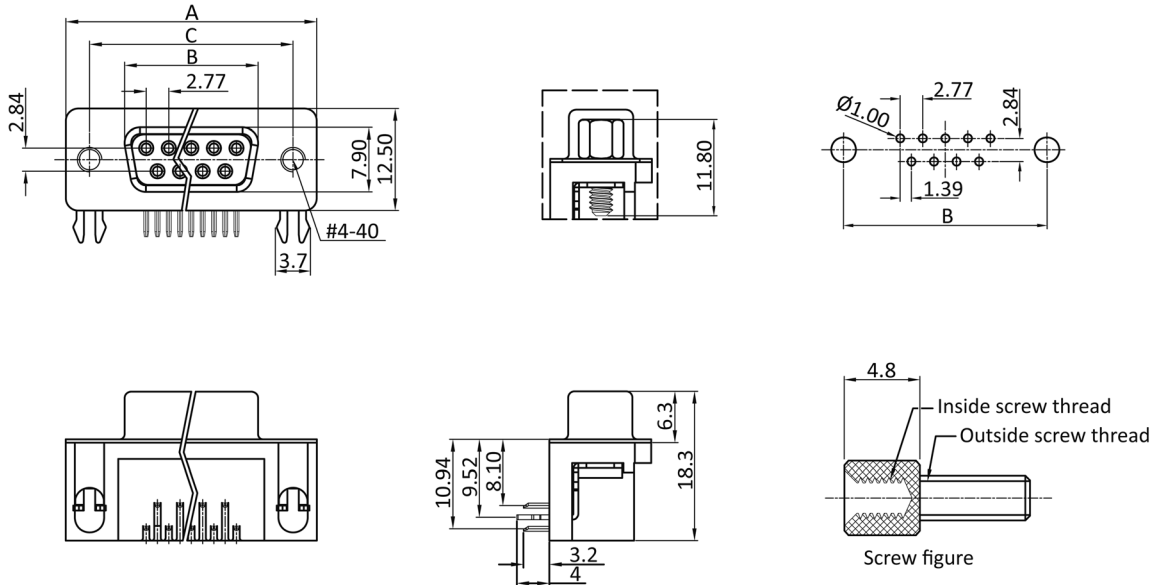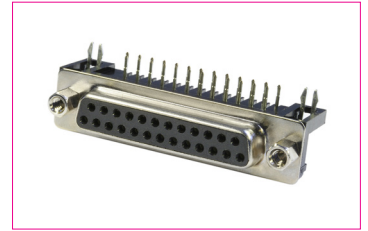

Dimensions

No. of contacts:	A:	B:	C:
9	30.84	16.33	24.99
15	39.14	24.66	33.32
25	53.04	38.38	47.04
37	69.32	54.84	63.50

Order-Information

Identifier:	No. of contacts:	Version:	Special:	Locking:
BU	#	WB	/ 7	#
D-Sub Female with Solder Pins	9: 9 pin 15: 15 pin 25: 25 pin 37: 37 pin	WB: angled	7: US norm	empty: with threaded bolts