

D-Sub High Density, Solder Cup

Female Connectors



RoHS
COMPLIANT

SPECIFICATION:

Current rating:	1 A
Insulation resistance:	500 MΩ min.
Contact resistance:	30 mΩ max.
Dielectric voltage:	500 V AC
Operation temperature:	-40 °C to +70 °C

MATERIAL:

Insulator:	PBT white UL94V-0
Shell:	Steel
Pins:	Brass

FINISH:





Contacts:	Gold Flash
Front shell:	Nickel plated
Rear shell:	Tin plated

HANDLING:

Processing:	Hand solering
Packing:	Tray

TOLERANCE:

.X	± 0.20
.XX	± 0.10

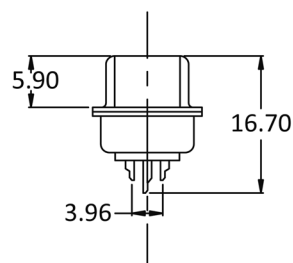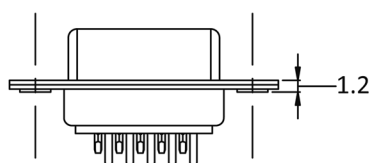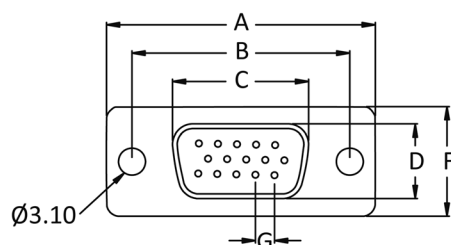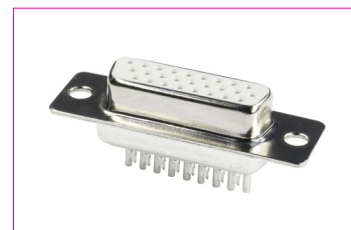

Dimensions

No. of contacts:	A:	B:	C:	D:	F:	G:
15	30.85	25.00	16.40	7.95	12.55	2.29
26	39.25	33.35	24.70	7.95	12.55	2.29
44	53.10	47.04	38.52	7.95	12.55	2.29
62	69.40	63.50	54.82	7.95	12.55	2.41
78	67.08	61.11	52.25	10.80	15.30	2.41

Order-Information

Identifier:	No. of contacts:	Version:
BU	#	HD
D-Sub High Density Female with Solder Cups	15: 15 pin	HD: High Density
	26: 26 pin	
	44: 44 pin	
	62: 62 pin	
	78: 78 pin	